


Kabel koneksi dengan soket

ADOGH030MSS0005E03

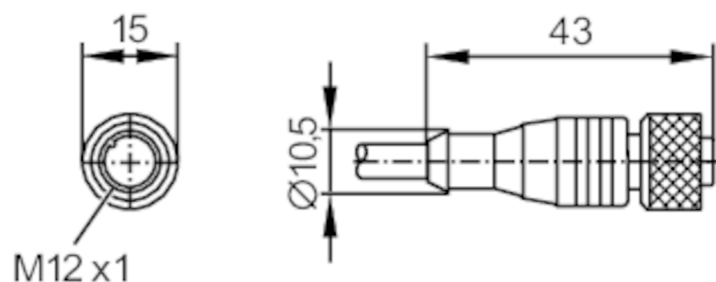

Data kelistrikan

Tegangan pengoperasian	[V]	< 250 AC / < 300 DC
------------------------	-----	---------------------

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67

Data teknis

Berat	[g]	198.3
Dimensi	[mm]	15 x 15 x 43
Material		TPU
Material bodi detakan		TPU
Material mur		kuningan, berlapis nikel

Keterangan

Jumlah paket		1 buah
--------------	--	--------

E10868



Kabel koneksi dengan soket

ADOGH030MSS0005E03

Koneksi listrik


Kabel: 5 m, PVC, oranye, Ø 5 mm; 3 x 0.34 mm² (19 x Ø 0.16 mm) / AWG 22

Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: C; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.5 Nm



Koneksi

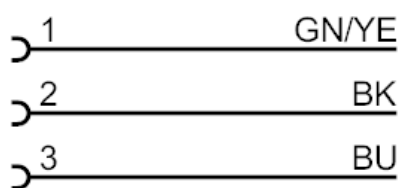

BK =	Warna core :
BU =	hitam
GN/YE =	biru
	hijau/kuning