


E10876



Kabel koneksi

VDOAH043MSS0002I04STGH040MSS

Produk tidak tersedia - entri arsip

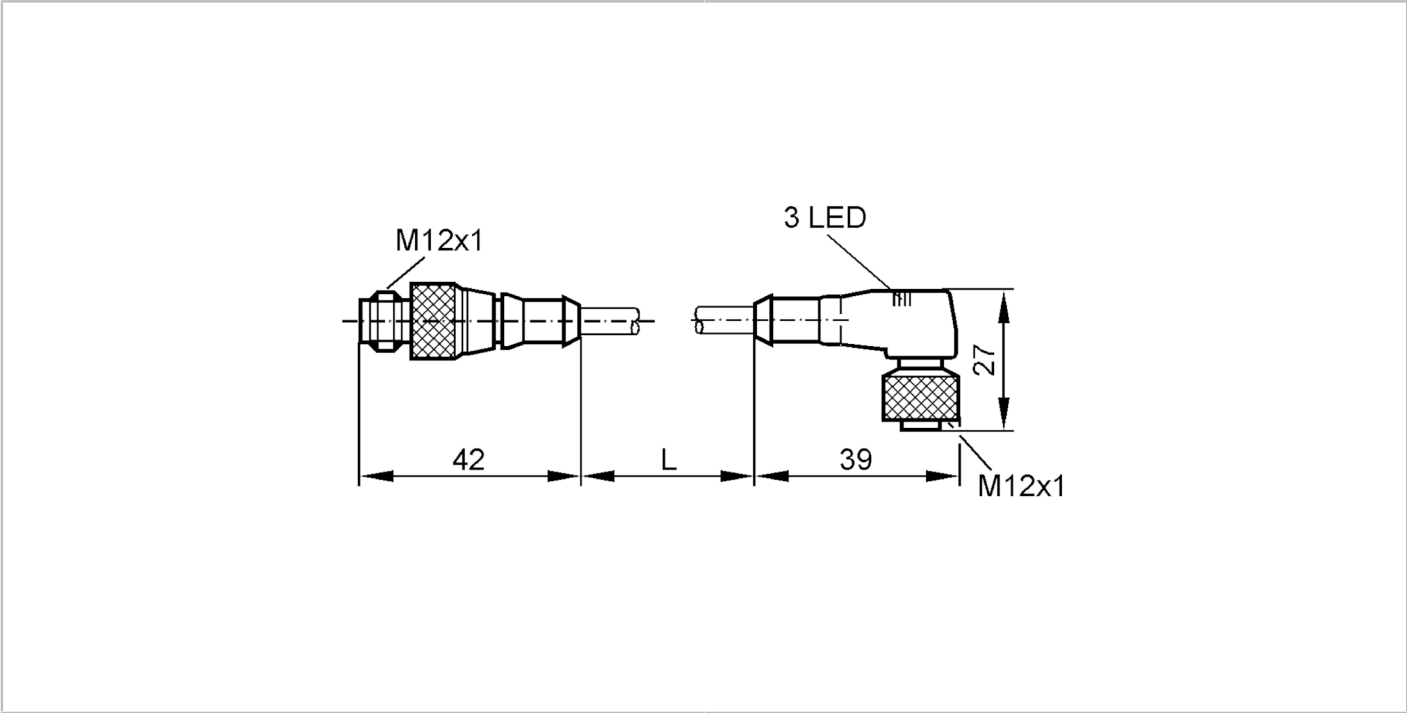

Aplikasi		
Fitur khusus	Bebas halogen	
Data kelistrikan		
Tegangan pengoperasian	[V]	10...30 DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan	IP 67	
Data teknis		
Material	TPU	
Material bodi detakan	TPU	
Material mur	kuningan, berlapis nikel	
Elemen display/pengoperasian		
Display	status peralihan	2 x LED, kuning
	operasi	1 x LED, hijau
Keterangan		
Jumlah paket	1 buah	

Kabel koneksi

VDOAH043MSS0002I04STGH040MSS

Koneksi listrik - colokan


Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.5 Nm



Koneksi listrik

Kabel: 2 m, PUR, Bebas halogen; terkoneksi silang; 4 x 0.34 mm² (19 x Ø 0.15 mm)

Koneksi

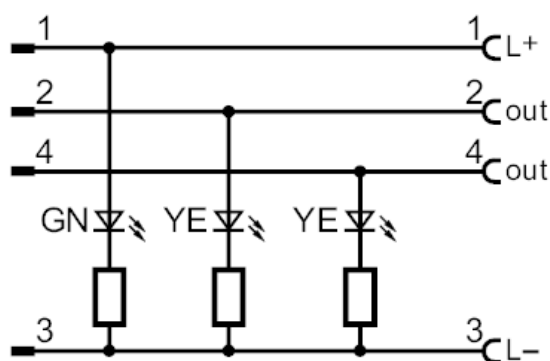

Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.5 Nm

