




Kabel koneksi dengan soket

ADOAF030ZDS0002A03

Produk tidak tersedia - entri arsip

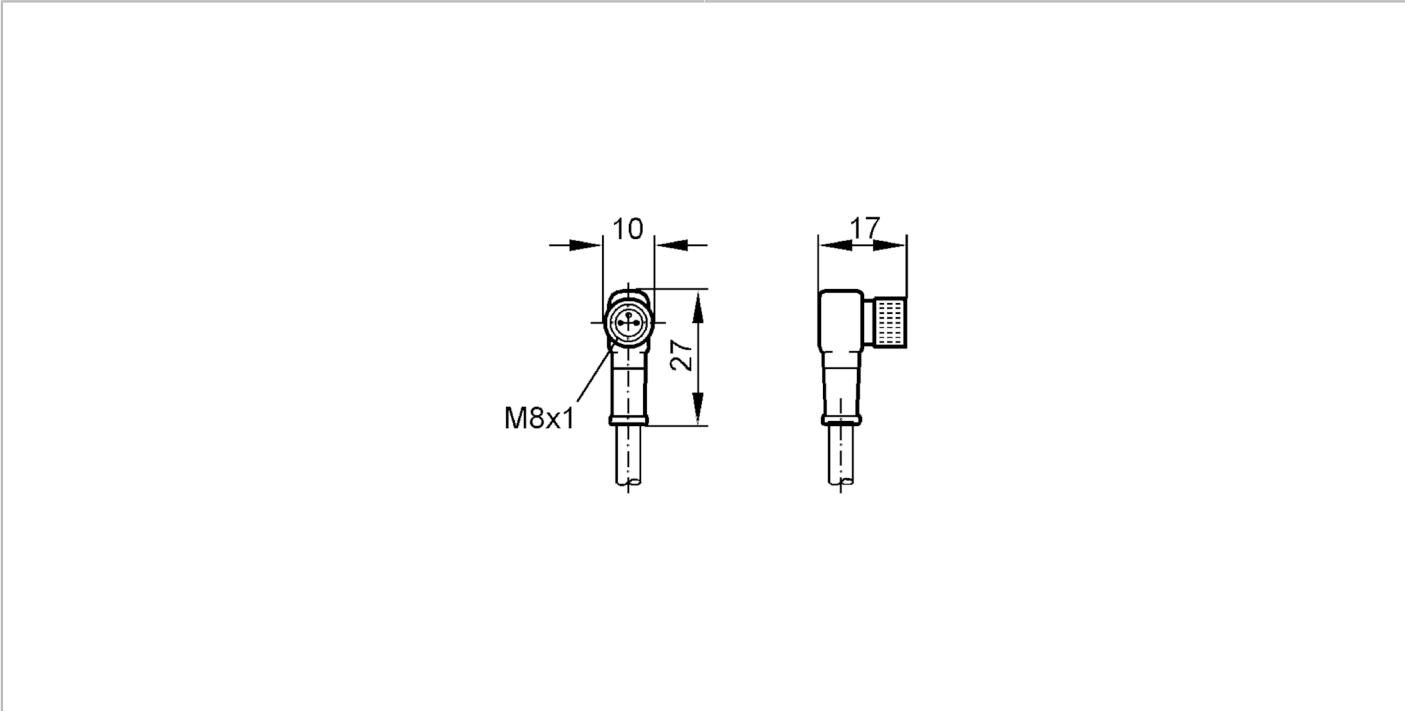

Data kelistrikan		
Tegangan pengoperasian	[V]	< 60 AC/DC
Kelas perlindungan		III


Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan		IP 68

Data teknis		
Dimensi	[mm]	17 x 10 x 27
Material		PUR
Material bodi detakan		PUR
Material mur		seng tuang

Keterangan		
Jumlah paket		1 buah

Koneksi listrik		
Kabel: 2 m, PUR / PVC, hitam, Ø 4.5 mm; 3 x 0.25 mm² (128 x Ø 0.05 mm)		

Koneksi listrik - soket		
Konektor: 1 x M8, bersiku; pengkodean: A; Bodi cetakan: PUR; Penguncian: seng tuang		

 


E10889



Kabel koneksi dengan soket

ADOAF030ZDS0002A03

Koneksi

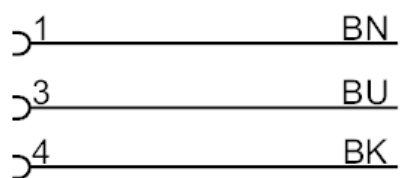

BN =	Warna core :	coklat
BK =		hitam
BU =		biru