


E10895



Kabel koneksi dengan soket

ADOGK120MSS0005A

Produk tidak tersedia - entri arsip

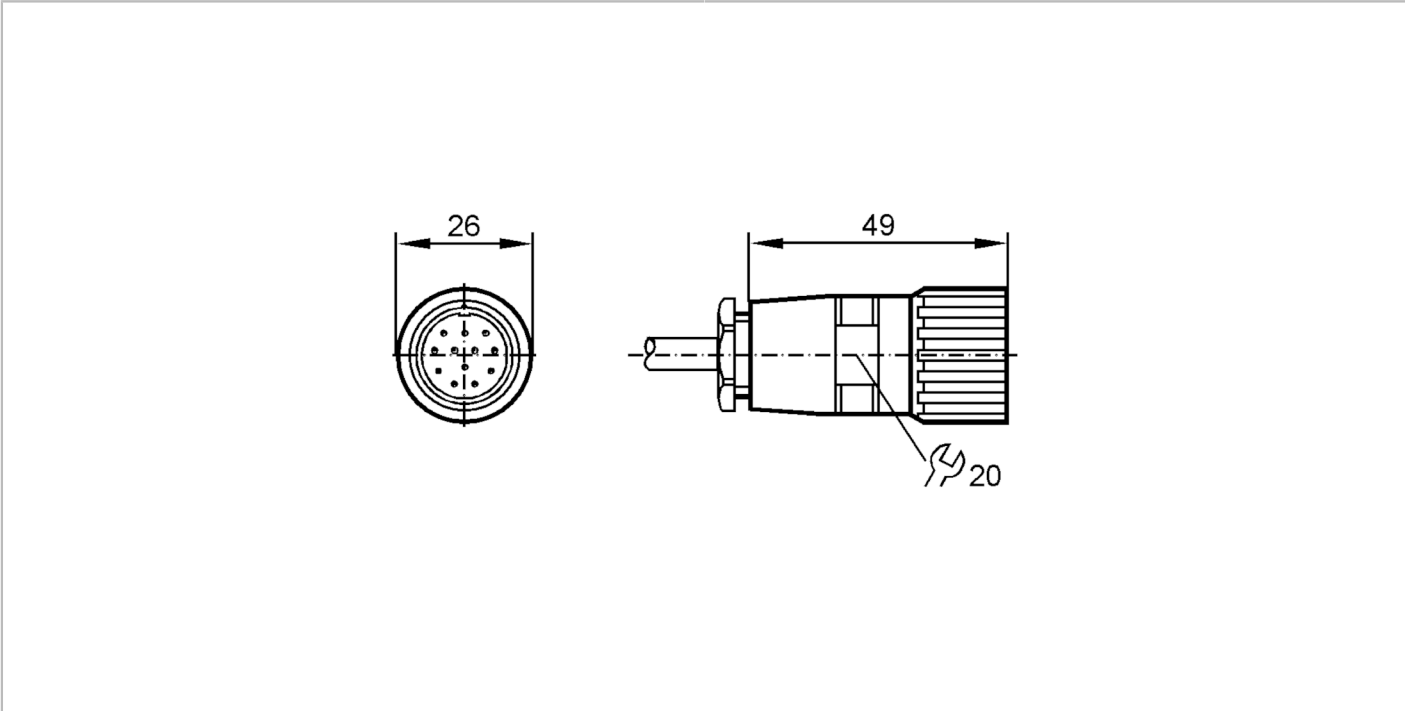

Data kelistrikan

Tegangan pengoperasian	[V]	10...30 DC
------------------------	-----	------------

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...90
Perlindungan		IP 65

Data teknis

Dimensi	[mm]	26 x 26 x 49
Material		kuningan berlapis nikel
Material bodi detakan		kuningan, berlapis nikel
Material mur		kuningan, berlapis nikel

Keterangan


Jumlah paket	1 buah
--------------	--------

Koneksi listrik

Kabel: 5 m, PUR; 12 x 1.0 mm² (128 x Ø 0.1 mm)

Koneksi listrik - soket

Konektor: 1 x M23, lurus; Bodi cetakan: kuningan, berlapis nikel; Penguncian: kuningan, berlapis nikel

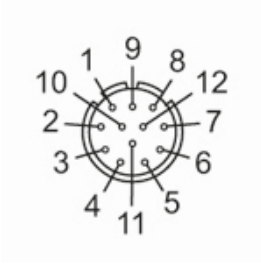

E10895



Kabel koneksi dengan soket

ADOGK120MSS0005A

Koneksi

1	BK 1
2	BK 2
3	BK 3
4	BK 4
5	BK 5
6	BK 6
7	BK 7
8	BK 8
9	BK 9
10	BK 10
11	BK 11
12	GN/YE