


E10897




Kabel koneksi dengan soket

ADOAK120MSS0005A

Produk tidak tersedia - entri arsip

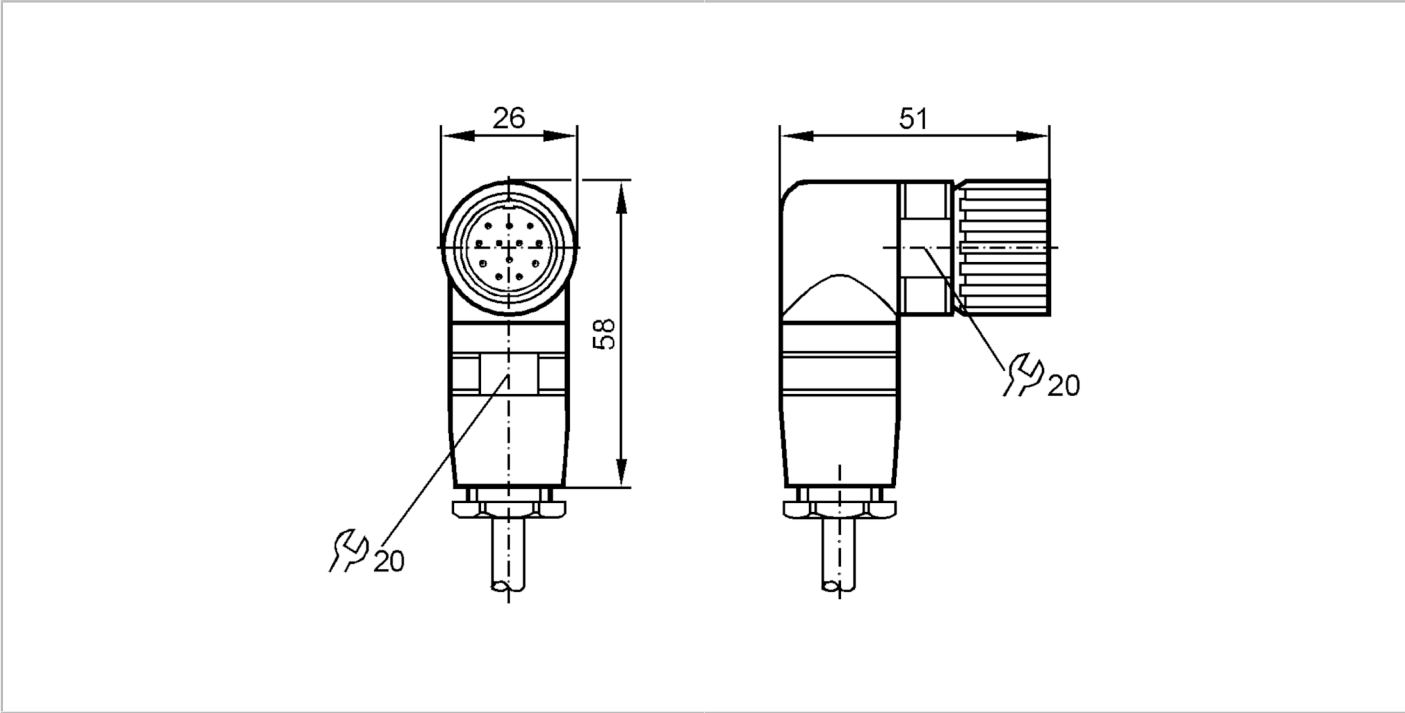

Data kelistrikan		
Tegangan pengoperasian	[V]	10...30 DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan		IP 65
Data teknis		
Dimensi	[mm]	51 x 26 x 58
Material		kuningan berlapis nikel
Material bodi detakan		kuningan, berlapis nikel
Material mur		kuningan, berlapis nikel
Keterangan		
Jumlah paket		1 buah
Koneksi listrik		
Kabel: 5 m, PUR; 12 x 1.0 mm ² (128 x Ø 0.1 mm)		
Koneksi listrik - soket		
Konektor: 1 x M23, bersiku; Bodi cetakan: kuningan, berlapis nikel; Penguncian: kuningan, berlapis nikel		

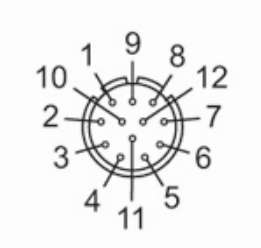

E10897



Kabel koneksi dengan soket

ADOAK120MSS0005A

Koneksi

1	BK 1
2	BK 2
3	BK 3
4	BK 4
5	BK 5
6	BK 6
7	BK 7
8	BK 8
9	BK 9
10	BK 10
11	BK 11
12	GN/YE