




Kabel koneksi dengan soket

ADOGF030VAS0010A03

Produk tidak tersedia - entri arsip

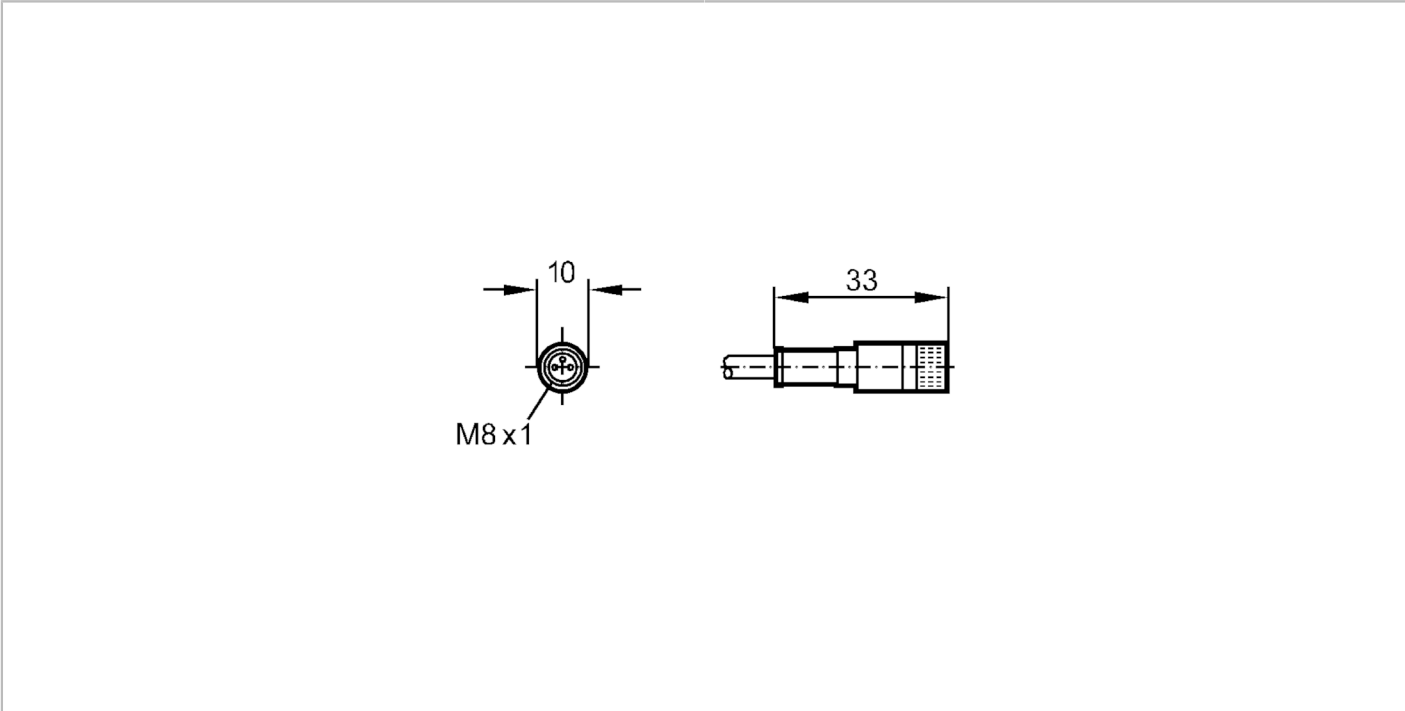

Data kelistrikan		
Tegangan pengoperasian	[V]	< 60 AC/DC
Kelas perlindungan		III


Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67

Data teknis		
Dimensi	[mm]	10 x 10 x 33
Material		PUR
Material bodi detakan		PUR
Material mur		baja tahan karat (1.4305/303)

Keterangan		
Jumlah paket		1 buah

Koneksi listrik		
Kabel: 10 m, PUR / PVC, hitam, Ø 4.5 mm; 3 x 0.25 mm² (128 x Ø 0.05 mm)		

Koneksi listrik - soket		
Konektor: 1 x M8, lurus; pengkodean: A; Bodi cetakan: PUR; Penguncian: baja tahan karat (1.4305/303)		

 


E10944



Kabel koneksi dengan soket

ADOGF030VAS0010A03

Koneksi

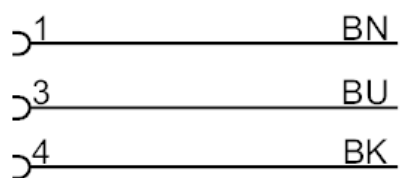

	Warna core :
BK =	hitam
BN =	coklat
BU =	biru