




Kabel jumper dengan soket katup

AVDAB031--S0002A03

Produk tidak tersedia - entri arsip

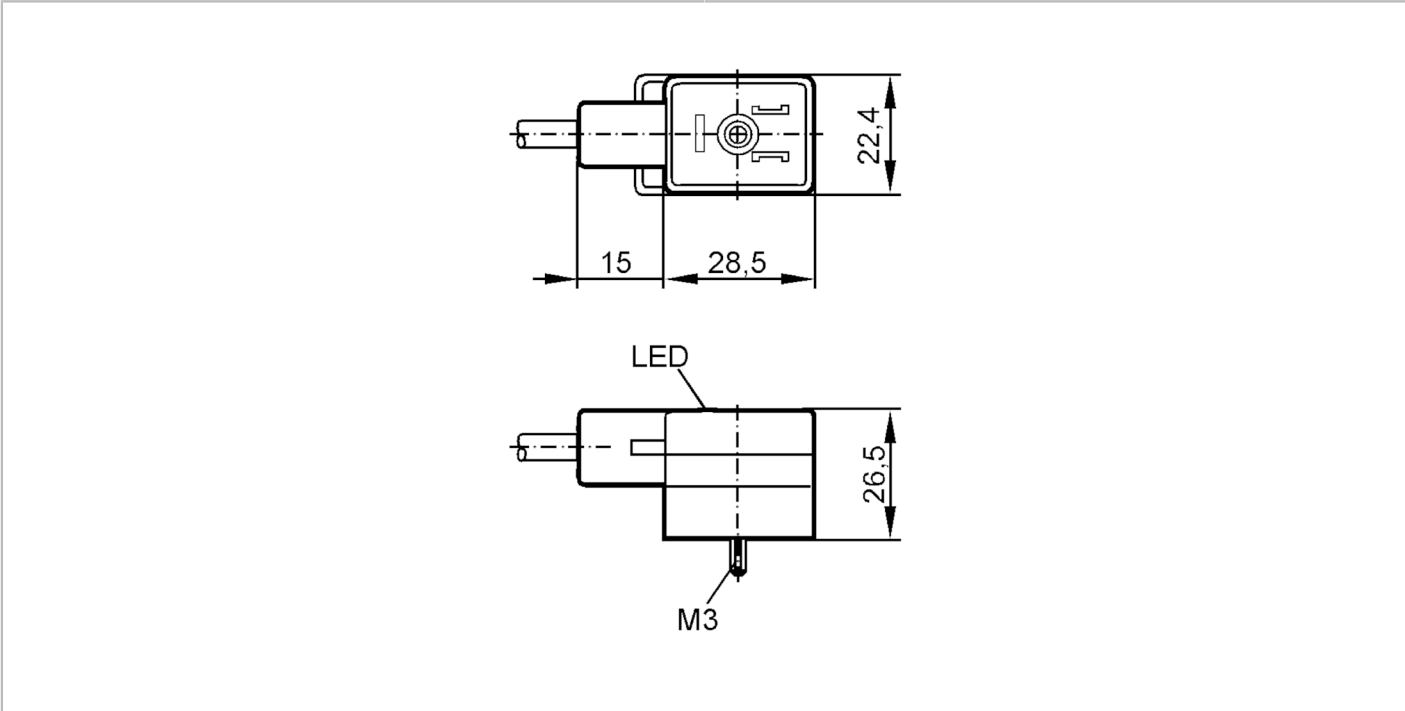

Data kelistrikan

Tegangan pengoperasian	[V]	< 24 AC/DC
Pelindung tegangan berlebih		ya; (VDR)

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67

Data teknis

Dimensi	[mm]	26.5 x 22.4 x 43.5
Material		PVC
Material bodi detakan		PVC
Material mur		baja tahan karat (1.4404 / 316L)

Keterangan

Jumlah paket		1 buah
--------------	--	--------

Koneksi listrik

Kabel: 2 m, PUR / PVC; 3 x 0.5 mm²

Koneksi listrik - soket

Konektor: 1 x katup tipe B DIN, bersiku; Bodi cetakan: PVC; Penguncian: baja tahan karat (1.4404 / 316L)




E10972



Kabel jumper dengan soket katup

AVDAB031--S0002A03

Koneksi

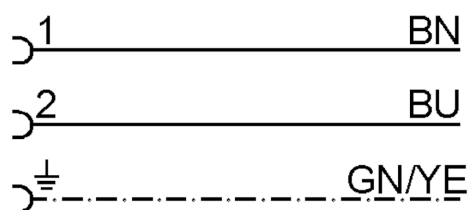

BN =	Warna core :
BU =	coklat
GN/YE =	biru
	hijau/kuning