



E10975



Kabel koneksi dengan soket

ADOGH080MSS0002A06

Produk tidak tersedia - entri arsip

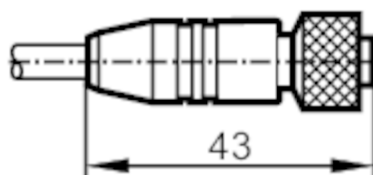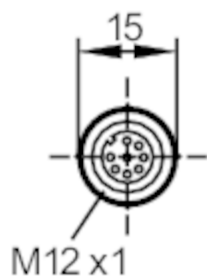

Data kelistrikan

Tegangan pengoperasian	[V]	< 30 AC / < 36 DC
Total beban arus maks.	[A]	3

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67

Data teknis

Dimensi	[mm]	15 x 15 x 43
Material		TPU
Material bodi detakan		TPU
Material mur		kuningan, berlapis nikel

Keterangan

Jumlah paket		1 buah
--------------	--	--------

E10975



Kabel koneksi dengan soket

ADOGH080MSS0002A06

Koneksi listrik

Kabel: 2 m, PUR / PVC, hitam, Ø 6 mm; 6 x 0.34 mm² (42 x Ø 0.1 mm)

Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel



Koneksi

1	WH
2	GN
3	YE
4	GY
5	BN
7	BU

	Warna core :
BN =	coklat
BU =	biru
GN =	hijau
GY =	abu-abu
WH =	putih
YE =	kuning