


Kabel koneksi dengan soket

ADOGH080MSS0010A06

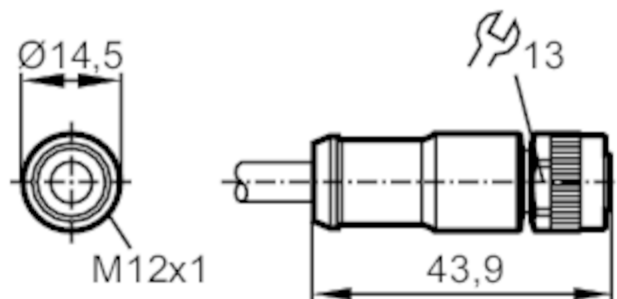

Data kelistrikan

Tegangan pengoperasian	[V]	< 60 AC/DC
Total beban arus maks.	[A]	2

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...85
Perlindungan		IP 68

Data teknis

Berat	[g]	468.7
Dimensi	[mm]	14.5 x 14.5 x 43.9
Material		TPU
Material bodi detakan		TPU
Material mur		seng tuang, berlapis nikel

Keterangan

Jumlah paket	1 buah
--------------	--------

E10977



Kabel koneksi dengan soket

ADOGH080MSS0010A06

Koneksi listrik

Kabel: 10 m, PUR, hitam, Ø 6 mm; 6 x 0.34 mm² (42 x Ø 0.1 mm)

Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: seng tuang, berlapis nikel



Koneksi

1	WH
2	GN
3	YE
4	GY
5	BN
7	BU

	Warna core :
BN =	coklat
BU =	biru
GN =	hijau
GY =	abu-abu
WH =	putih
YE =	kuning