


E10980



Kabel koneksi dengan soket

ADOAH080MSS0010A06

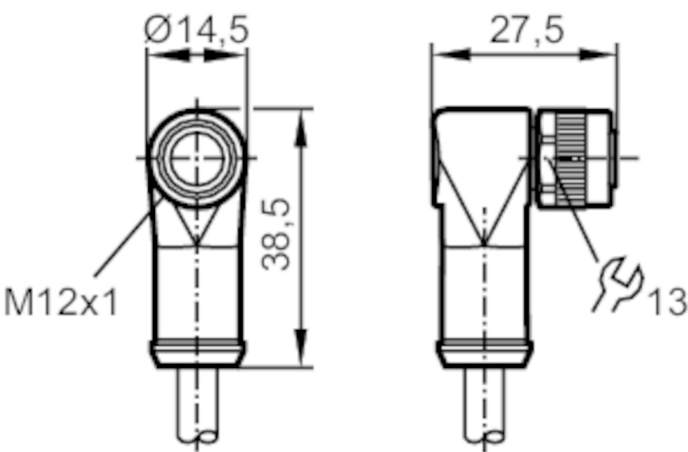

Data kelistrikan		
Tegangan pengoperasian	[V]	< 60 AC/DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...85
Perlindungan		IP 68
Data teknis		
Berat	[g]	479
Dimensi	[mm]	38.5 x 14.5 x 27.5
Material		TPU
Material bodi detakan		TPU
Material mur		seng tuang, berlapis nikel
Keterangan		
Jumlah paket		1 buah

E10980



Kabel koneksi dengan soket

ADOAH080MSS0010A06

Koneksi listrik

Kabel: 10 m, PUR, hitam; 6 x 0.34 mm² (42 x Ø 0.1 mm)

Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: TPU; Penguncian: seng tuang, berlapis nikel



Koneksi

1	WH
2	GN
3	YE
4	GY
5	BN
7	BU

	Warna core :
BN =	coklat
BU =	biru
GN =	hijau
GY =	abu-abu
WH =	putih
YE =	kuning