


E10981



Soket berkabel

SDOGA030PLSFKPG

Produk tidak tersedia - entri arsip

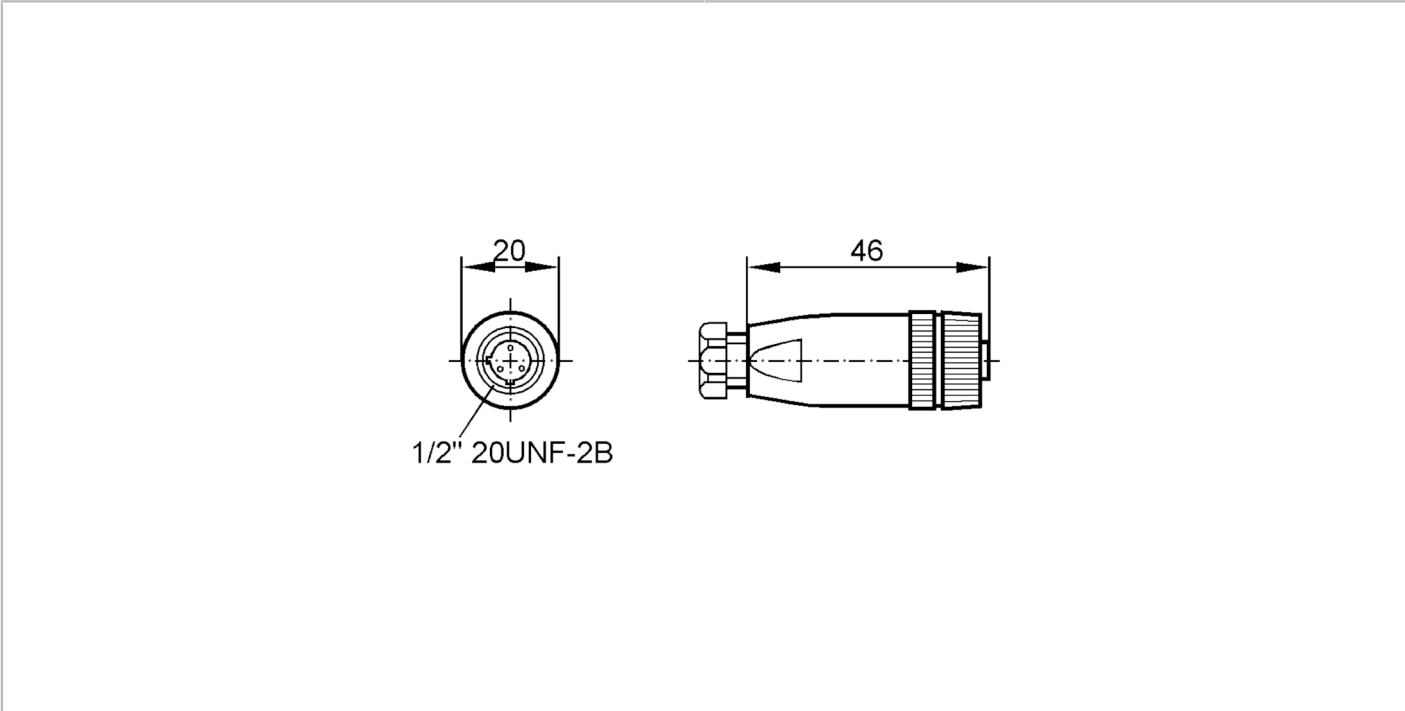

Data kelistrikan

Tegangan pengoperasian	[V]	10...55 DC
------------------------	-----	------------

Kondisi pengoperasian

Suhu sekitar	[°C]	-40...85
Perlindungan		IP 67

Data teknis

Dimensi	[mm]	20 x 20 x 46
Material		PA
Material bodi detakan		PA
Material mur		kuningan, berlapis nikel

Keterangan


Jumlah paket	1 buah
--------------	--------

Koneksi listrik

terminal: ...0.75 mm²; Konektor kabel: PG 11

Koneksi listrik - soket

Konektor: 1 x 1/2", lurus; pengkodean: C; Bodi cetakan: PA; Penguncian: kuningan, berlapis nikel

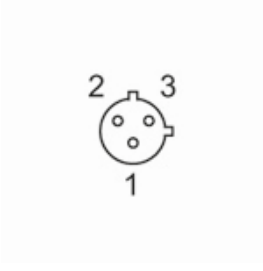

E10981

Soket berkabel

SDOGA030PLSFKPG



Koneksi

