




Kabel koneksi

VDOAF030MSS0005H03STGH030MSS

Produk tidak tersedia - entri arsip

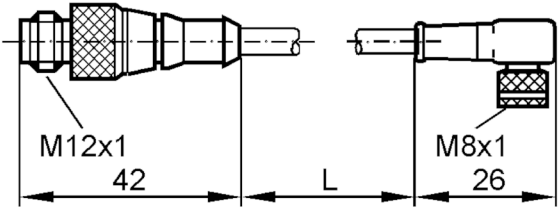

Aplikasi	
Fitur khusus	Bebas halogen
Data kelistrikan	
Tegangan pengoperasian [V]	10...30 DC
Kelas perlindungan	III
Kondisi pengoperasian	
Suhu sekitar [°C]	-25...90
Perlindungan	IP 67
Data teknis	
Material	TPU
Material bodi detakan	TPU
Material mur	kuningan, berlapis nikel
Keterangan	
Jumlah paket	1 buah
Koneksi listrik - colokan	

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel



E10992




Kabel koneksi

VDOAF030MSS0005H03STGH030MSS

Koneksi listrik

Kabel: 5 m, PUR, Bebas halogen, hitam, Ø 4.3 mm; 3 x 0.34 mm² (43 x Ø 0.1 mm)

Koneksi

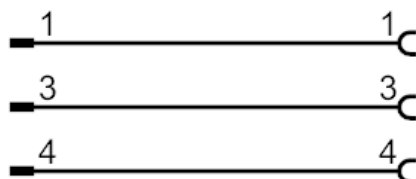

Koneksi listrik - soket

Konektor: 1 x M8, bersiku; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel

