


Kabel koneksi dengan soket

ADOAH042ZDS0002E03

Produk tidak tersedia - entri arsip

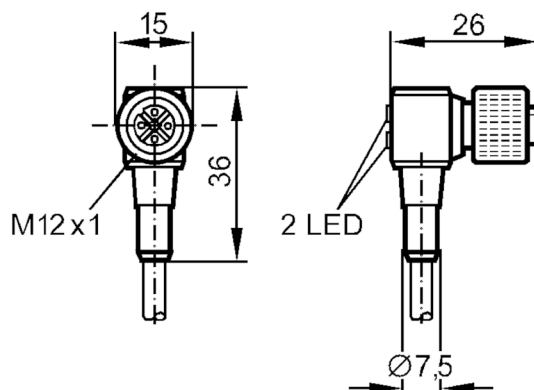

Data kelistrikan

Tegangan pengoperasian	[V]	10...30 DC
------------------------	-----	------------

Output

Desain kelistrikan	NPN
--------------------	-----

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...90
--------------	------	----------

Perlindungan	IP 67
--------------	-------

Data teknis

Dimensi	[mm]	36 x 15 x 26
---------	------	--------------

Material	PUR
----------	-----

Material bodi detakan	PUR
-----------------------	-----

Material mur	seng tuang, berlapis nikel
--------------	----------------------------

Elemen display/pengoperasian

Display	status peralihan	1 x LED, kuning
	operasi	1 x LED, hijau

Keterangan

Jumlah paket	1 buah
--------------	--------

E10007



Kabel koneksi dengan soket

ADOAH042ZDS0002E03

Koneksi listrik


Kabel: 2 m, PVC, hitam, Ø 4.5 mm; 3 x 0.34 mm² (182 x Ø 0.05 mm)

Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: PUR; Penguncian: seng tuang, berlapis nikel



Koneksi

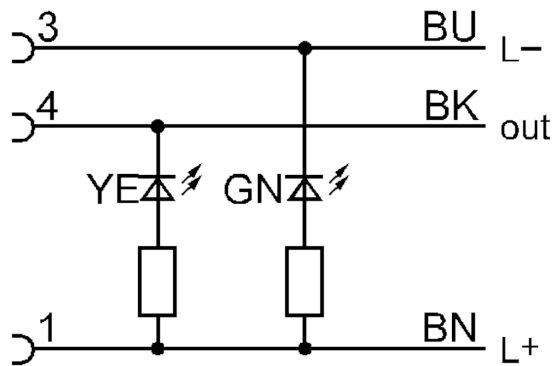

BN =
BK =
BU =

Warna core :
coklat
hitam
biru