


E10011



Kabel koneksi dengan soket

ADOAH042ZDS0010E03

Produk tidak tersedia - entri arsip

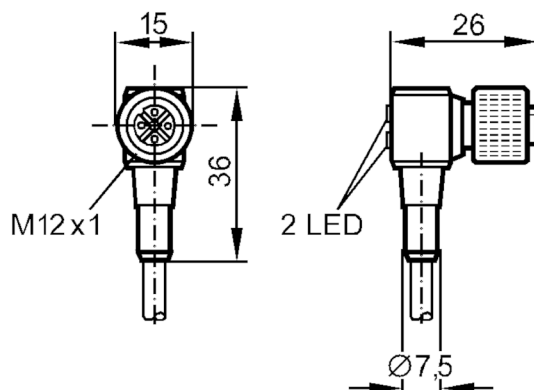

Data kelistrikan

Tegangan pengoperasian [V] 10...30 DC

Output

Desain kelistrikan NPN

Kondisi pengoperasian

Suhu sekitar [°C] -25...90

Perlindungan IP 67

Data teknis

Dimensi [mm] 36 x 15 x 26

Material PUR

Material bodi detakan PUR

Material mur seng tuang, berlapis nikel

Elemen display/pengoperasian

Display	status peralihan	1 x LED, kuning
	operasi	1 x LED, hijau

Keterangan

Jumlah paket 1 buah

E10011



Kabel koneksi dengan soket

ADOAH042ZDS0010E03

Koneksi listrik


Kabel: 10 m, PVC, hitam, Ø 4.5 mm; 3 x 0.34 mm² (182 x Ø 0.05 mm)

Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: PUR; Penguncian: seng tuang, berlapis nikel



Koneksi

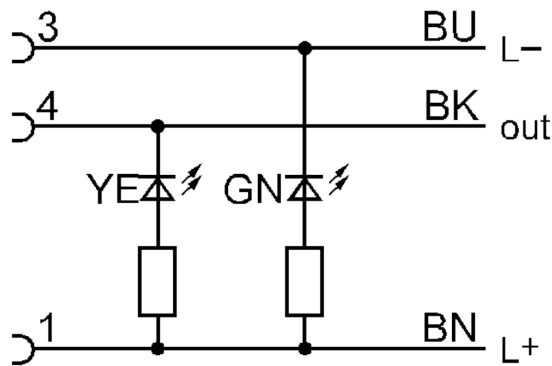

BN =
BK =
BU =

Warna core :
coklat
hitam
biru