


E10085



Soket berkabel

SDOAT052--SFKPG

Produk tidak tersedia - entri arsip

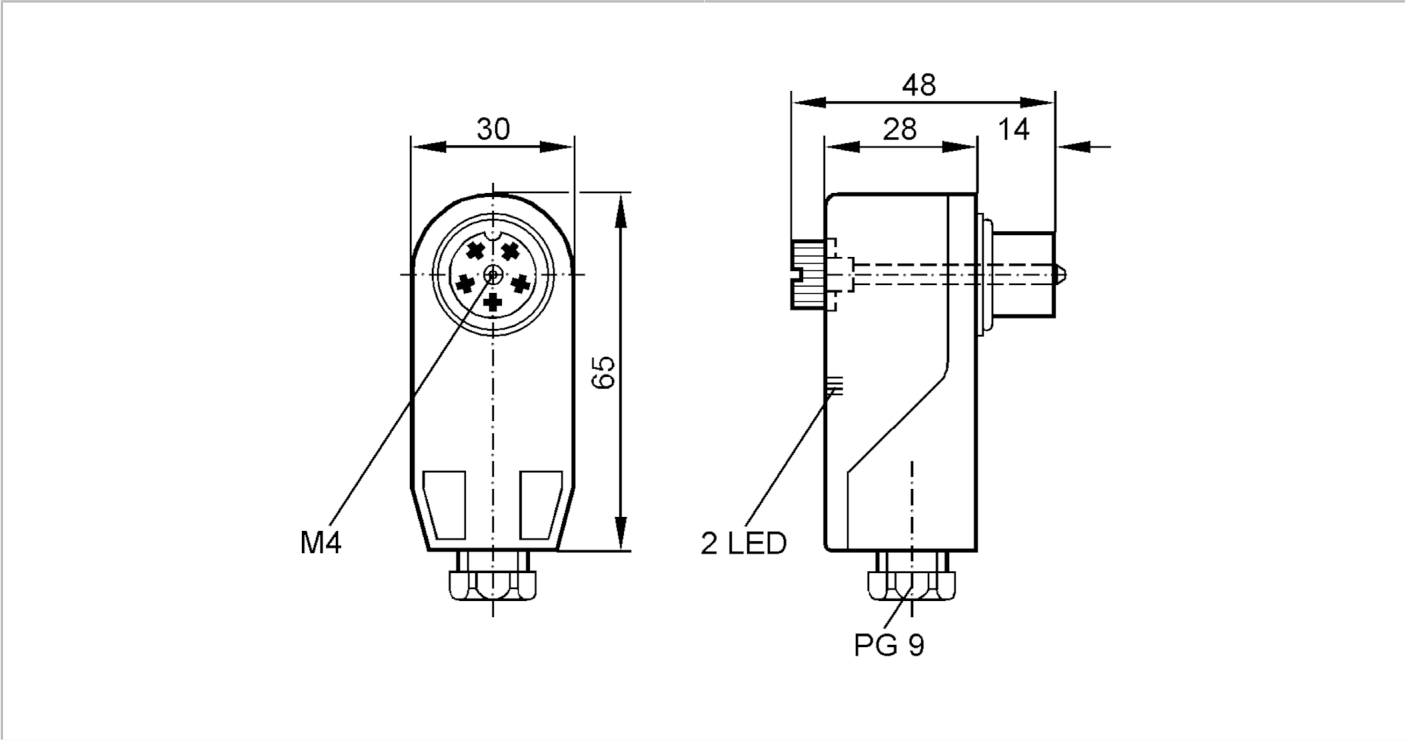

Data kelistrikan		
Tegangan pengoperasian	[V]	10...30 DC
Output		
Desain kelistrikan		NPN
Kondisi pengoperasian		
Suhu sekitar	[°C]	-30...80
Perlindungan		IP 65
Data teknis		
Dimensi	[mm]	48 x 30 x 65
Material		PA
Material bodi detakan		PA
Material mur		PA
Elemen display/pengoperasian		
Display	status peralihan	1 x LED, kuning
	operasi	1 x LED, hijau
Keterangan		
Jumlah paket		1 buah

E10085



Soket berkabel

SDOAT052--SFKPG

Koneksi listrik

terminal: ...1.5 mm²; Konektor kabel: PG 9

Koneksi listrik - soket

Konektor: 1 x Ø 28 mm, bersiku; pengkodean: A; Bodi cetakan: PA; Penguncian: PA



Koneksi

