


Soket berkabel

SDOAT052--SFKPG

Produk tidak tersedia - entri arsip

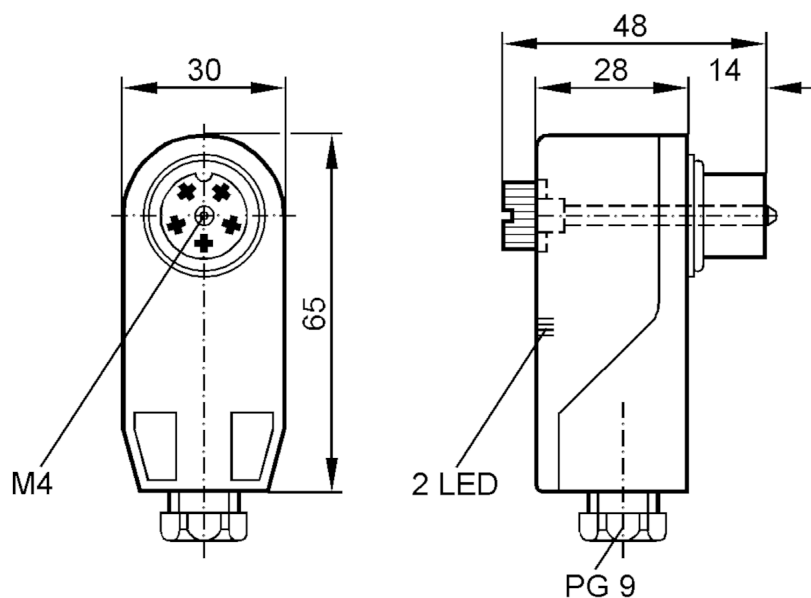

Data kelistrikan

Tegangan pengoperasian	[V]	10...30 DC
------------------------	-----	------------

Output

Desain kelistrikan	NPN
--------------------	-----

Kondisi pengoperasian

Suhu sekitar	[°C]	-30...80
--------------	------	----------

Perlindungan	IP 65
--------------	-------

Data teknis

Dimensi	[mm]	48 x 30 x 65
---------	------	--------------

Material	PA
----------	----

Material bodi detakan	PA
-----------------------	----

Material mur	PA
--------------	----

Elemen display/pengoperasian

Display	status peralihan	1 x LED, kuning
	operasi	1 x LED, hijau

Keterangan

Jumlah paket	1 buah
--------------	--------



Soket berkabel

SDOAT052--SFKPG

Koneksi listrik

terminal: ...1.5 mm²; Konektor kabel: PG 9

Koneksi listrik - soket

Konektor: 1 x Ø 28 mm, bersiku; pengkodean: A; Bodi cetakan: PA; Penguncian: PA



Koneksi

