




Soket berkabel

SDOAT050--SFKPG

Produk tidak tersedia - entri arsip

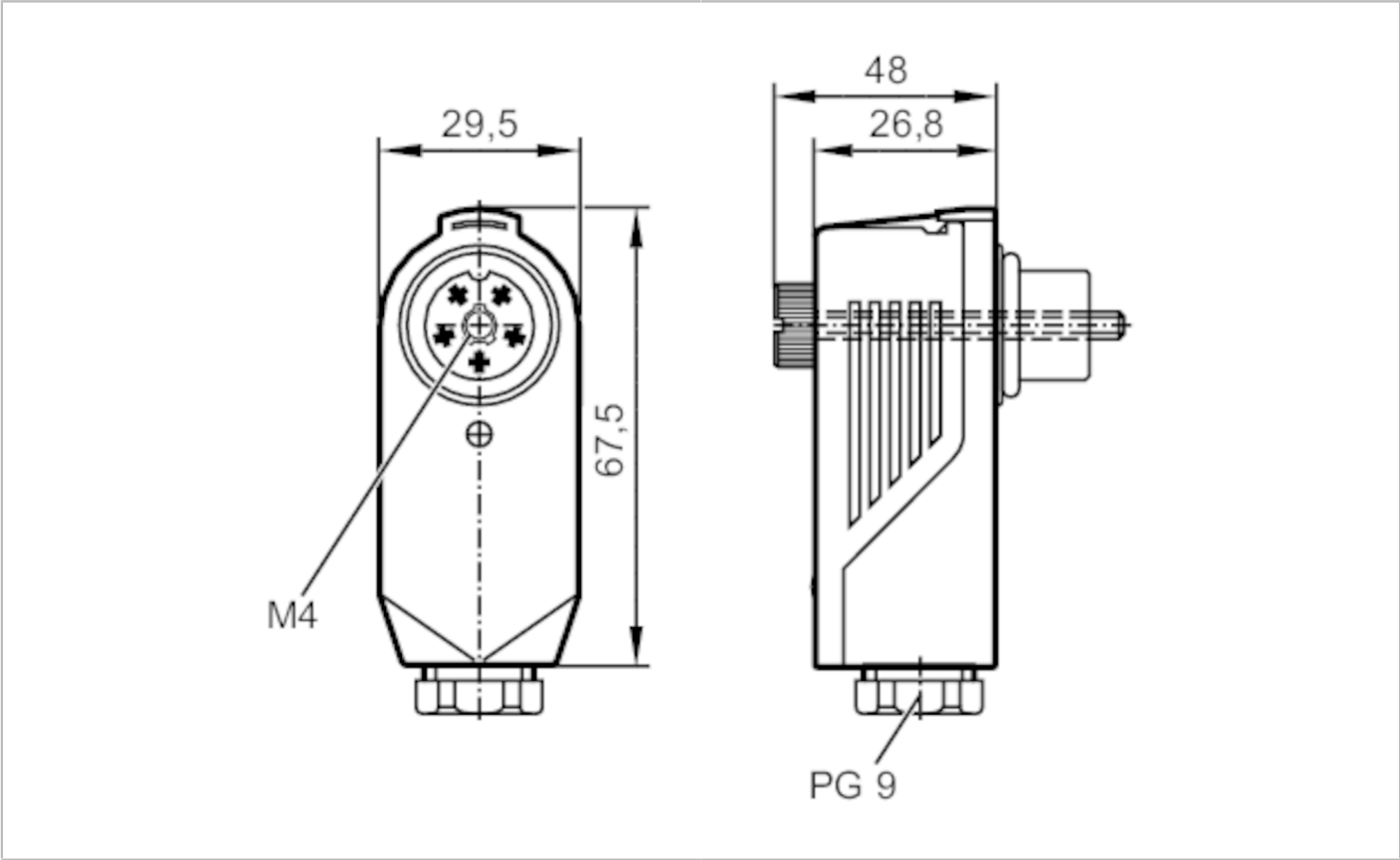

Data kelistrikan		
Tegangan pengoperasian	[V]	20...250 AC/DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...80
Perlindungan		IP 65
Data teknis		
Berat	[g]	65.2
Material		PA
Material bodi detakan		PA
Keterangan		
Jumlah paket		1 buah

E10087



Soket berkabel

SDOAT050--SFKPG

Koneksi listrik

terminal: ...1.5 mm²; Selubung kabel: Ø 5...11 mm

Koneksi listrik - soket

Konektor: 1 x Ø 28 mm, bersiku; pengkodean: A; Bodi cetakan: PA



Koneksi

