


E10099



Soket berkabel

SDOAH041PLSFKPG

Produk tidak tersedia - entri arsip

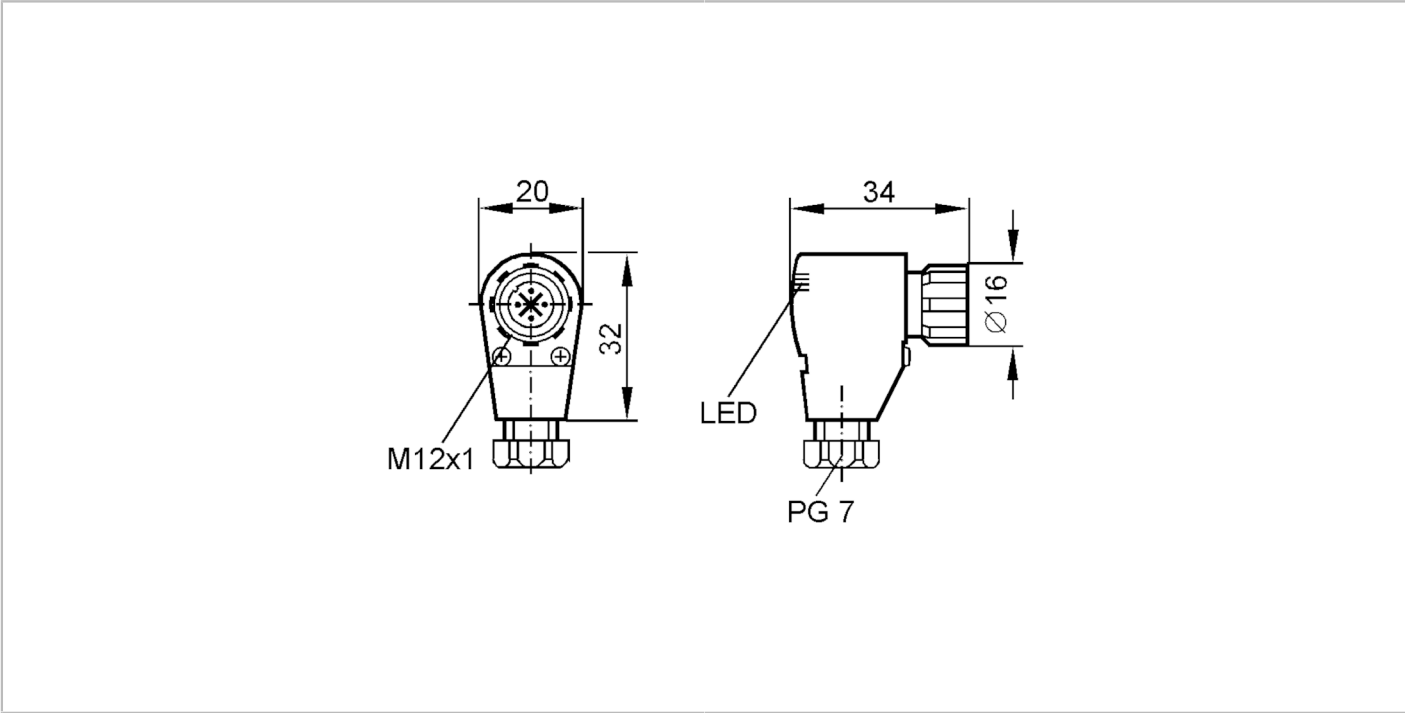

Data kelistrikan		
Tegangan pengoperasian	[V]	10...30 DC
Output		
Desain kelistrikan		NPN
Kondisi pengoperasian		
Suhu sekitar	[°C]	-30...80
Perlindungan		IP 65
Data teknis		
Dimensi	[mm]	20 x 34 x 32
Material		PA
Material bodi detakan		PA
Material mur		PA
Elemen display/pengoperasian		
Display	status peralihan	1 x LED, kuning
Keterangan		
Jumlah paket		1 buah

**Soket berkabel**

SDOAH041PLSFKPG

Koneksi listrikterminal: ...0.5 mm²; Konektor kabel: PG 7**Koneksi listrik - soket**

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: PA; Penguncian: PA

**Koneksi**