



## Colokan adaptor

ESTGB030MSS00,3E03 (PG13,5)

Produk tidak tersedia - entri arsip

# No scale drawing available

## Aplikasi

Fitur khusus

Kontak berlapis emas

## Data kelistrikan

Tegangan pengoperasian

[V]

&lt; 600 AC/DC

## Kondisi pengoperasian

Suhu sekitar

[°C]

-20...100

Perlindungan

IP 68

## Data teknis

Berat

[g]

45.36

Ulir pemasangan

1/2" NPT

Material

aluminium dianodisasi

Material bodi detakan

aluminium, dianodisasi

## Keterangan

Jumlah paket

 
1 buah

## Koneksi listrik

, PVC; 3 x 1.5 mm<sup>2</sup> / AWG 16

## Koneksi listrik - colokan

Konektor: 1 x 7/8", lurus; pengkodean: A; Bodi cetakan: aluminium, dianodisasi; Kontak: dilapisi emas




# E10103



## Colokan adaptor

ESTGB030MSS00,3E03 (PG13,5)

### Koneksi

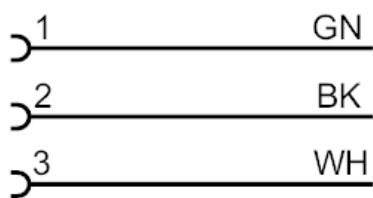

|      |              |       |
|------|--------------|-------|
| BK = | Warna core : | hitam |
| GN = |              | hijau |
| WH = |              | putih |