


E10108



Soket berkabel

SDOAH040PLSFKPG

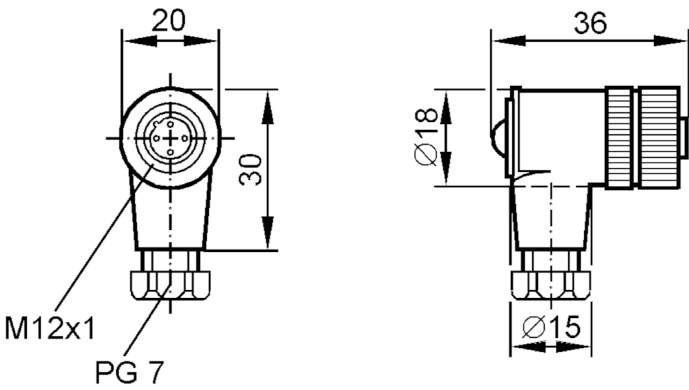

Data kelistrikan		
Tegangan pengoperasian	[V]	< 250 AC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-40...85
Perlindungan		IP 67
Data teknis		
Berat	[g]	15.2
Dimensi	[mm]	36 x 20 x 30
Material		PBT
Material bodi detakan		PBT
Material mur		PA
Keterangan		
Jumlah paket		1 buah

E10108



Soket berkabel

SDOAH040PLSFKPG

Koneksi listrik

terminal sekrup: ...0.5 mm²; Konektor kabel: PG 7

Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: B; Bodi cetakan: PBT; Penguncian: PA



Koneksi

