


Colokan adaptor

ESTGB040MSS00,3E03 (PG13,5)

Produk tidak tersedia - entri arsip

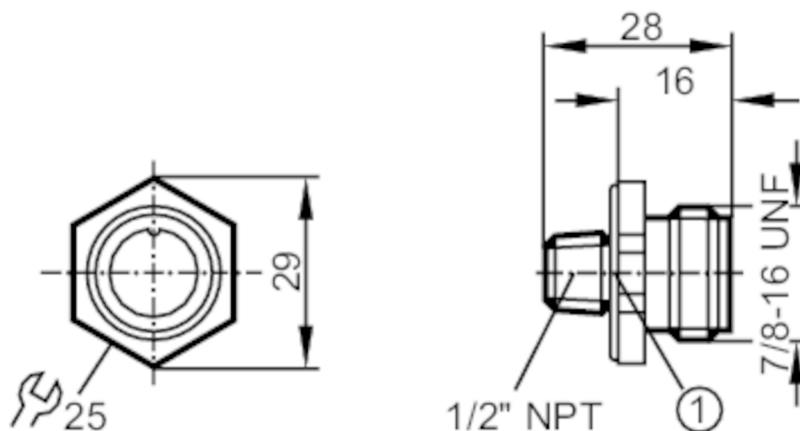

1 O-ring

Aplikasi

Fitur khusus

Kontak berlapis emas

Data kelistrikan

Tegangan pengoperasian

[V]

< 600 AC/DC

Kondisi pengoperasian

Suhu sekitar

[°C]

-20...100

Perlindungan

IP 68

Data teknis

Berat

[g]

45.5

Ulir pemasangan

1/2" NPT

Material

aluminium dianodisasi

Material bodi detakan

aluminium, dianodisasi

Keterangan

Jumlah paket

1 buah



Colokan adaptor

ESTGB040MSS00,3E03 (PG13,5)

Koneksi listrik


, PVC; 4 x 0.34 mm² / AWG 22

Koneksi listrik - colokan

Konektor: 1 x 7/8", lurus; pengkodean: A; Bodi cetakan: aluminium, dianodisasi; Kontak: dilapisi emas



Koneksi

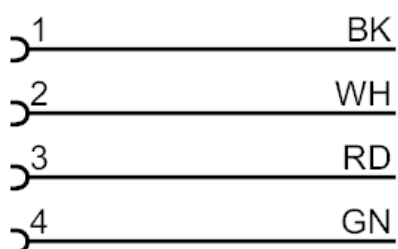

BK =	Warna core :	hitam
GN =		hijau
RD =		merah
WH =		putih