


E10128



Kabel koneksi dengan soket

ADOAH040PLS0005E03

Produk tidak tersedia - entri arsip

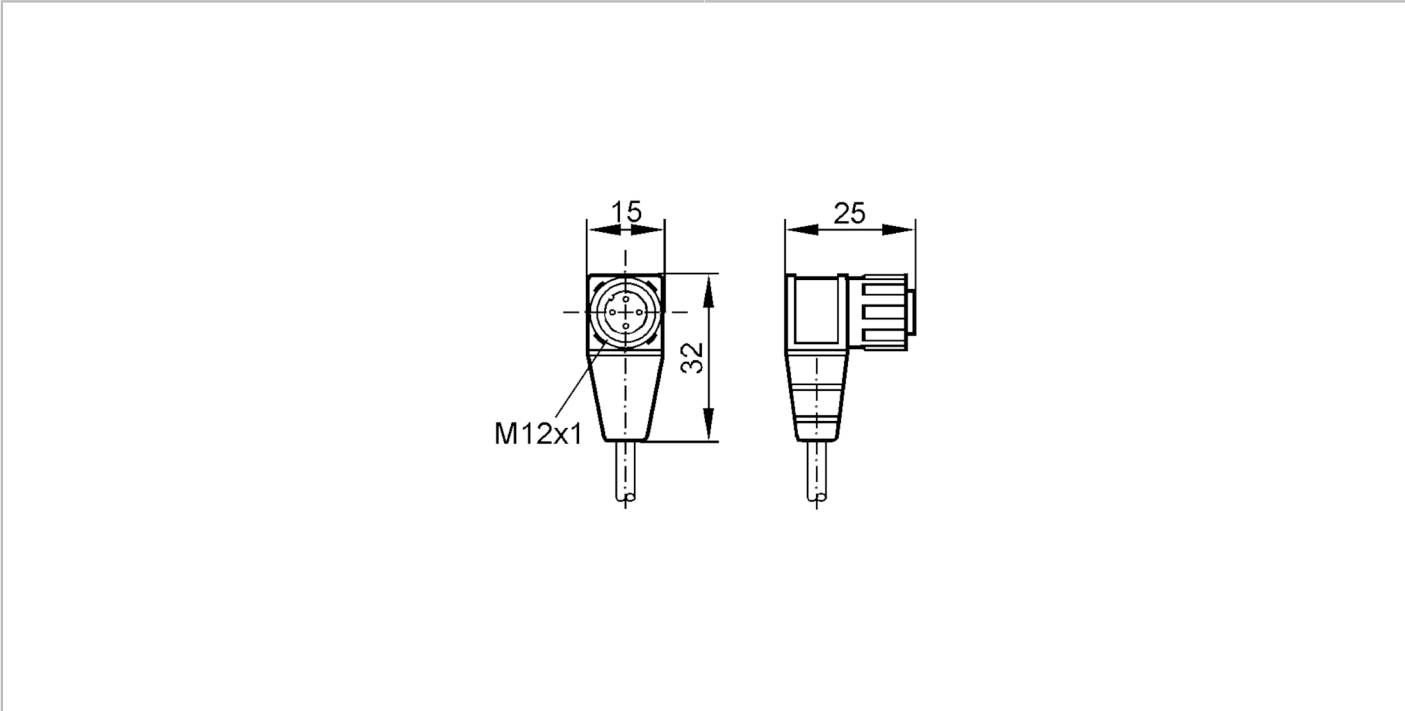

Data kelistrikan		
Tegangan pengoperasian	[V]	10...55 DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-40...90
Perlindungan		IP 67
Data teknis		
Dimensi	[mm]	25 x 15 x 32
Material		PUR
Material bodi detakan		PUR
Material mur		PUR
Keterangan		
Jumlah paket		1 buah
Koneksi listrik		
Kabel: 5 m, PVC; 3 x 0.34 mm ² (7 x Ø 0.25 mm)		
Koneksi listrik - soket		
Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: PUR; Penguncian: PUR		



E10128



Kabel koneksi dengan soket

ADOAH040PLS0005E03

Koneksi

