


E10136



Soket berkabel

SDOGH042PLSFKPG

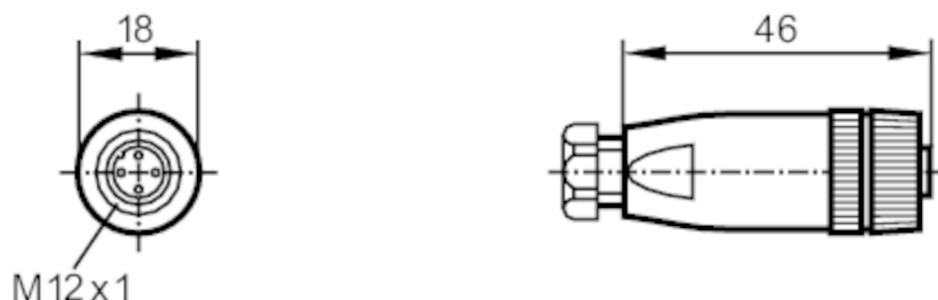

Data kelistrikan

Tegangan pengoperasian	[V]	10...30 DC
------------------------	-----	------------

Output

Desain kelistrikan	PNP
--------------------	-----

Kondisi pengoperasian

Suhu sekitar	[°C]	-40...85
Perlindungan		IP 67

Data teknis

Berat	[g]	14
Dimensi	[mm]	18 x 18 x 46
Material		PA
Material bodi detakan		PA
Material mur		PA

Elemen display/pengoperasian

Display	status peralihan	1 x LED, kuning
	operasi	1 x LED, hijau

Keterangan

Jumlah paket	1 buah
--------------	--------

E10136



Soket berkabel

SDOGH042PLSFKPG

Koneksi listrik

terminal sekrup: ...0.75 mm²; Selubung kabel: Ø 4...6 mm

Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PA; Penguncian: PA



Koneksi

