


E10137



Soket berkabel

SDOGJ040PLSFKPG

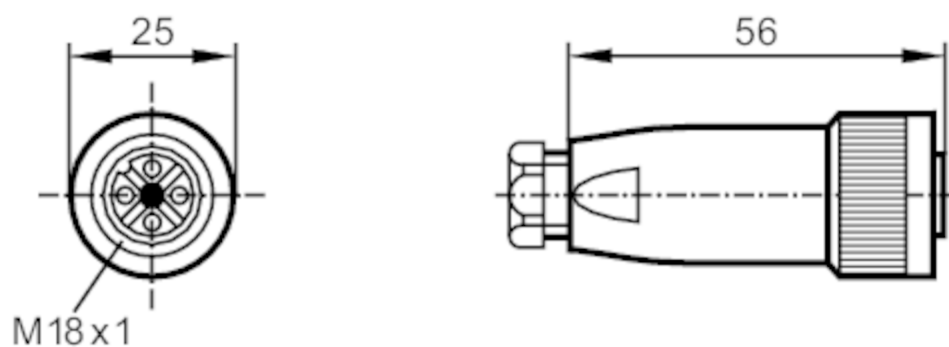

Data kelistrikan

Tegangan pengoperasian	[V]	< 250 AC/DC
Total beban arus maks.	[A]	4; (...40 °C)

Kondisi pengoperasian

Suhu sekitar	[°C]	-40...85
Perlindungan		IP 65

Data teknis

Berat	[g]	26.6
Dimensi	[mm]	25 x 25 x 56
Material		PA
Material bodi detakan		PA
Material mur		ULTRAMID

Keterangan

Jumlah paket		1 buah
--------------	--	--------

E10137



Soket berkabel

SDOGJ040PLSFKPG

Koneksi listrik

terminal: ...0.75 mm²; Selubung kabel: Ø 6...8 mm

Koneksi listrik - soket

Konektor: 1 x M18, lurus; pengkodean: A; Bodi cetakan: PA; Penguncian: ULTRAMID



Koneksi

