


E10170



Kabel koneksi dengan soket

ADOAH042MSS0010E03

Produk tidak tersedia - entri arsip

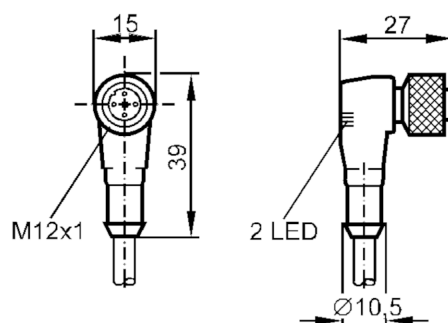

Data kelistrikan

Tegangan pengoperasian [V] 10...30 DC

Output

Desain kelistrikan PNP

Kondisi pengoperasian

Suhu sekitar [°C] -25...80

Perlindungan IP 67

Data teknis

Dimensi [mm] 27 x 15 x 39

Material TPU transparan

Material bodi detakan TPU, transparan

Material mur kuningan, berlapis nikel

Elemen display/pengoperasian

Display	status peralihan	1 x LED, kuning
	operasi	1 x LED, hijau

Keterangan

Jumlah paket 1 buah

E10170



Kabel koneksi dengan soket

 
ADOAH042MSS0010E03

Koneksi listrik


Kabel: 10 m, PVC, oranye, Ø 5 mm; 3 x 0.34 mm²

Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: TPU, transparan; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.5 Nm



Koneksi

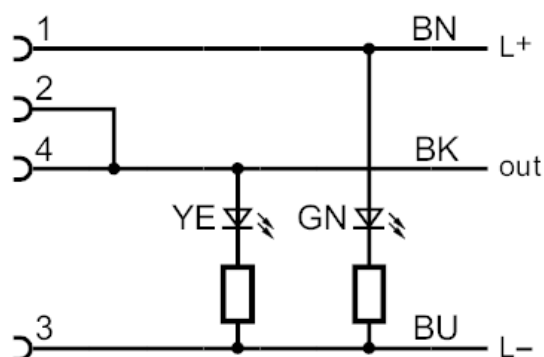

Warna core :
BN = coklat
BK = hitam
BU = biru