


E10200



Kabel koneksi dengan soket

ADOAA030MSS0005E03

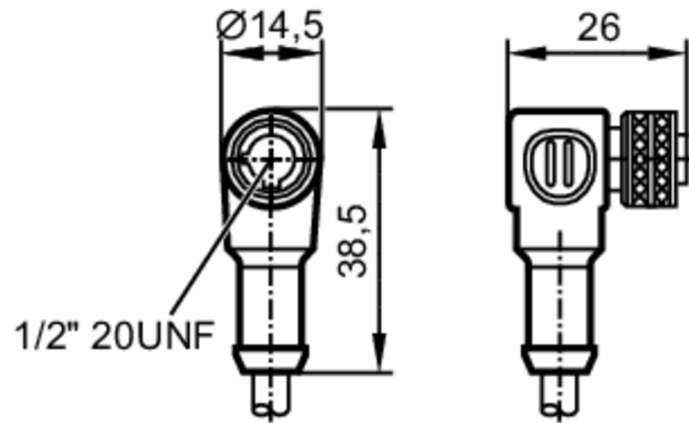

Aplikasi

Fitur khusus	Kesesuaian rantai tarik
--------------	-------------------------

Data kelistrikan

Tegangan pengoperasian	[V]	< 250 AC/DC
Total beban arus maks.	[A]	4; (40° C)

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...85
Perlindungan		IP 67

Pengujian/persetujuan

Persetujuan UL	Ta	< 75 °C
	Nomor file UL	E191684

Data teknis

Berat	[g]	197.8
Dimensi	[mm]	26 x 14.5 x 38.5
Material		TPU hitam
Material bodi detakan		TPU
Material mur		kuningan, berlapis nikel
Kesesuaian rantai tarik		ya
Kesesuaian rantai tarik	radius pembengkokan untuk penggunaan yang fleksibel	min. 10 x diameter kabel
	kecepatan pergerakan	maks. 3,3 m/dtk untuk panjang pergerakan horizontal 5 m dan akselerasi maks. 5 m/dtk ²
	siklus pembengkokan	> 2 Mio.
	ketegangan torsional	± 180 °/m

E10200



Kabel koneksi dengan soket

ADOAA030MSS0005E03

Keterangan

Jumlah paket

1 buah

Koneksi listrik


Kabel: 5 m, PVC, kuning, Ø 5.2 mm; 3 x (42 x Ø 0.1 mm) / AWG 22

Koneksi listrik - soket

Konektor: 1 x 1/2", bersiku; pengkodean: C; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel



Koneksi

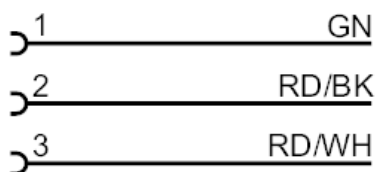

GN =	Warna core :
RD/BK =	hijau
RD/WH =	merah/hitam
	merah/putih