




Kabel koneksi dengan soket


ADOGA030MSS0005B03

Produk tidak tersedia - entri arsip

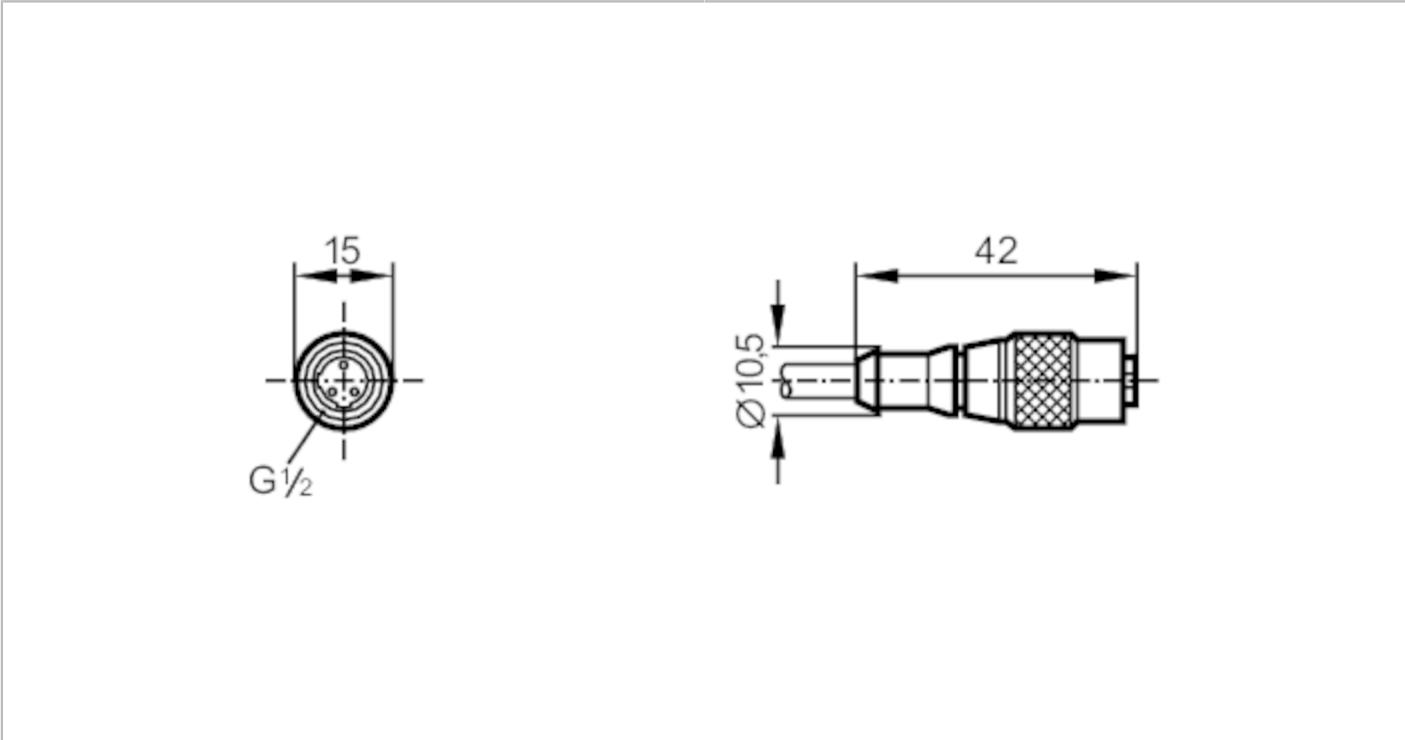

Data kelistrikan		
Tegangan pengoperasian	[M]	< 250 AC / < 300 DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67
Data teknis		
Dimensi	[mm]	15 x 15 x 42
Material		TPU
Material bodi detakan		TPU
Material mur		kuningan, berlapis nikel
Keterangan		
Jumlah paket		1 buah
Koneksi listrik		
Kabel: 5 m, PUR, oranye, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)		
Koneksi listrik - soket		

Konektor: 1 x 1/2", lurus; pengkodean: C; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel

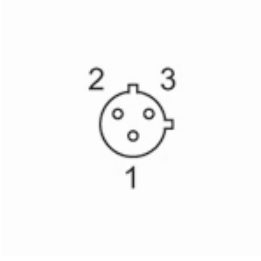


E10212



Kabel koneksi dengan soket

ADOGA030MSS0005B03

Koneksi

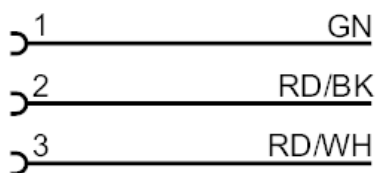

GN =	Warna core :
RD/BK =	hijau
RD/WH =	merah/hitam
	merah/putih