


E10262



Kabel koneksi dengan soket

ADOAA030MSS0010B03

Produk tidak tersedia - entri arsip

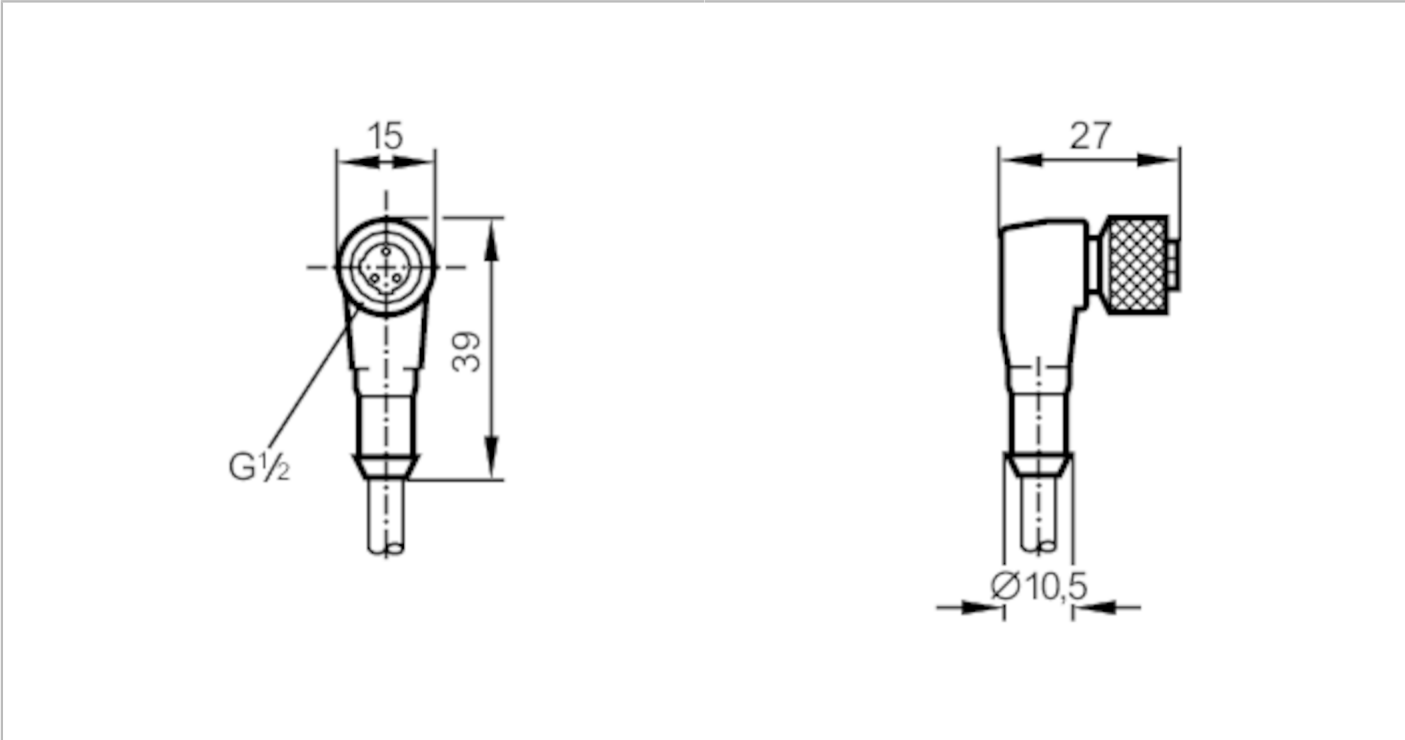

Data kelistrikan		
Tegangan pengoperasian	[M]	< 250 AC / < 300 DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67
Data teknis		
Material		TPU
Material bodi detakan		TPU
Material mur		kuningan, berlapis nikel
Keterangan		
Jumlah paket		1 buah

Koneksi listrik

Kabel: 10 m, PUR, oranye, Ø 5.2 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Koneksi listrik - soket

Konektor: 1 x 1/2", bersiku; pengkodean: C; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel




E10262



Kabel koneksi dengan soket

ADOAA030MSS0010B03

Koneksi

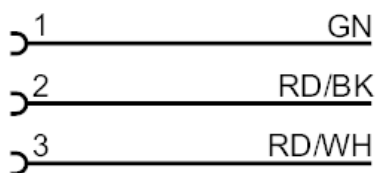

GN =	Warna core :
RD/BK =	hijau
RD/WH =	merah/hitam
	merah/putih