

Kabel koneksi dengan soket

ADOAF032MSS0002A03

Produk tidak tersedia - entri arsip



Data kelistrikan

Tegangan pengoperasian [V]	10...30 DC
Kelas perlindungan	III

Output

Desain kelistrikan	PNP
--------------------	-----

Kondisi pengoperasian

Suhu sekitar [°C]	-25...90
Perlindungan	IP 67

Data teknis

Dimensi [mm]	17 x 10 x 26
Material	TPU transparan
Material bodi detakan	TPU, transparan
Material mur	kuningan, berlapis nikel

Elemen display/pengoperasian

Display	status peralihan	1 x LED, kuning
	operasi	1 x LED, hijau

Keterangan

Jumlah paket	1 buah
--------------	--------

E10274



Kabel koneksi dengan soket

ADOAF032MSS0002A03

Koneksi listrik


Kabel: 2 m, PUR / PVC, oranye, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Koneksi listrik - soket

Konektor: 1 x M8, bersiku; pengkodean: A; Bodi cetakan: TPU, transparan; Penguncian: kuningan, berlapis nikel



Koneksi

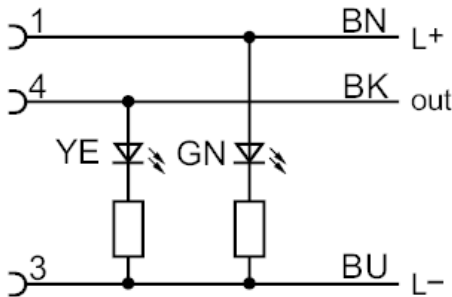

BN =
BK =
BU =

Warna core :
coklat
hitam
biru