


E10283



Kotak splitter

ZDO8H059MSS0010H11

Produk tidak tersedia - entri arsip

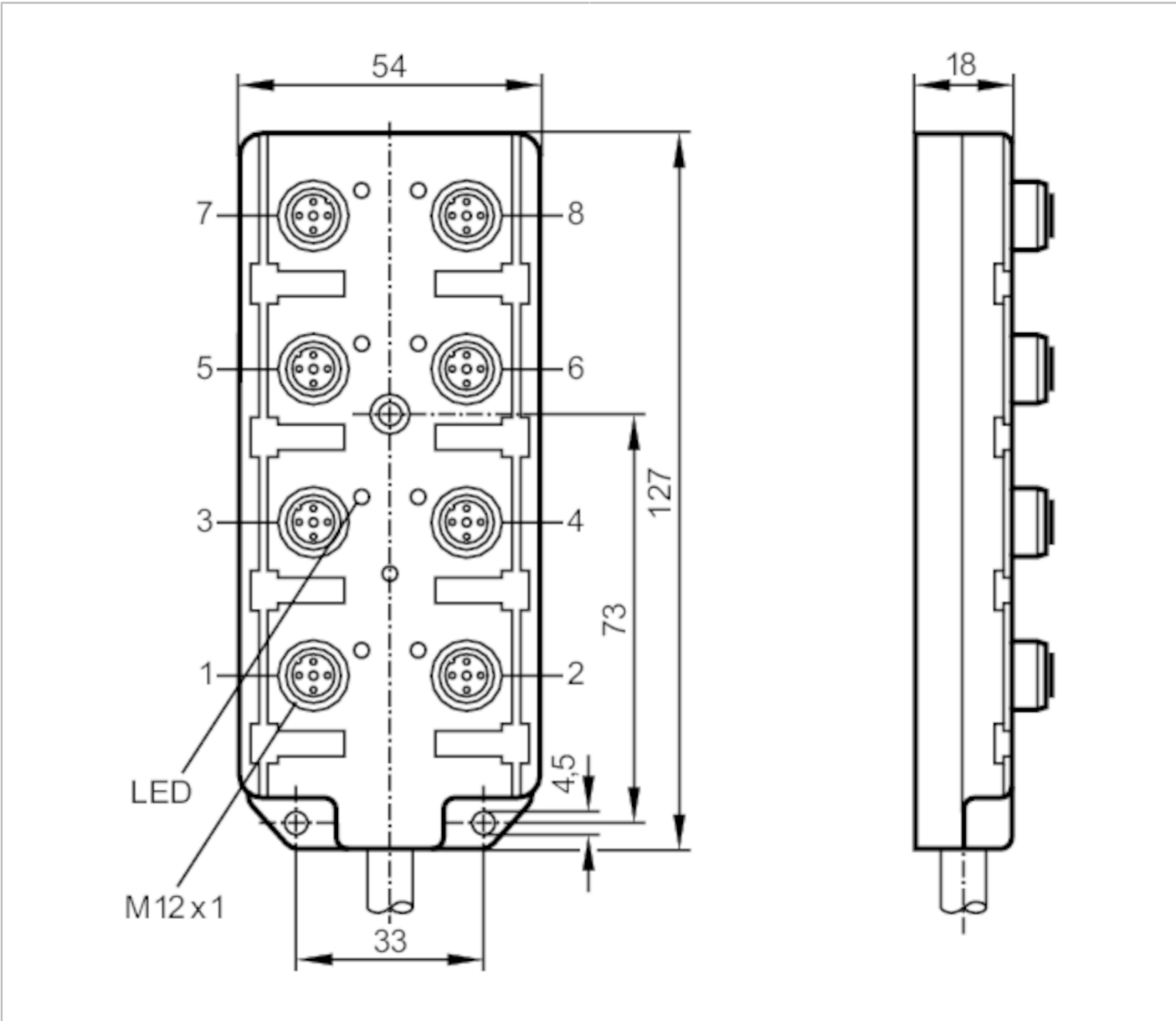



Aplikasi		
Fitur khusus	Bebas dari silikon; Bebas halogen; Kontak berlapis emas	
Bebas dari silikon	ya	
Data kelistrikan		
Tegangan pengoperasian	[V]	10...30 DC
Kelas perlindungan		II
Beban arus maks. per modul/slot	[A]	4
Total beban arus maks.	[A]	12
Kondisi pengoperasian		
Suhu sekitar	[°C]	-15...80
Perlindungan		IP 67



Kotak splitter

ZDO8H059MSS0010H11

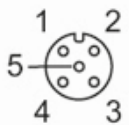Data teknis		
Dimensi	[mm]	18 x 54 x 127
Material		TPU
Material bodi detakan		TPU
Jumlah port kotak splitter		8
Tipe konektor		M12
Elemen display/pengoperasian		
Display	status peralihan	8 x LED, kuning
	operasi	1 x LED, hijau
Keterangan		
Jumlah paket		1 buah
Koneksi listrik		
Kabel: 10 m, PUR, Bebas halogen, hitam, Ø 9 mm; 8 x 0.34 mm ² + 3 x 0.75 mm ²		
Koneksi listrik - slot		
Konektor: 8 x M12; pengkodean: A; Bodi cetakan: TPU; Kontak: dilapisi emas; Torsi pengencangan: 0.5 Nm		
		

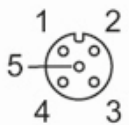



Kotak splitter

ZDO8H059MSS0010H11

Koneksi



	Warna core :
BK =	hitam
BN =	coklat
BU =	biru
GN =	hijau
GN/YE =	hijau/kuning
GY =	abu-abu
PK =	merah muda
RD =	merah
VT =	ungu
WH =	putih
YE =	kuning