


E10290



Kotak splitter

ZDO4H045MSS0,03A07

Produk tidak tersedia - entri arsip

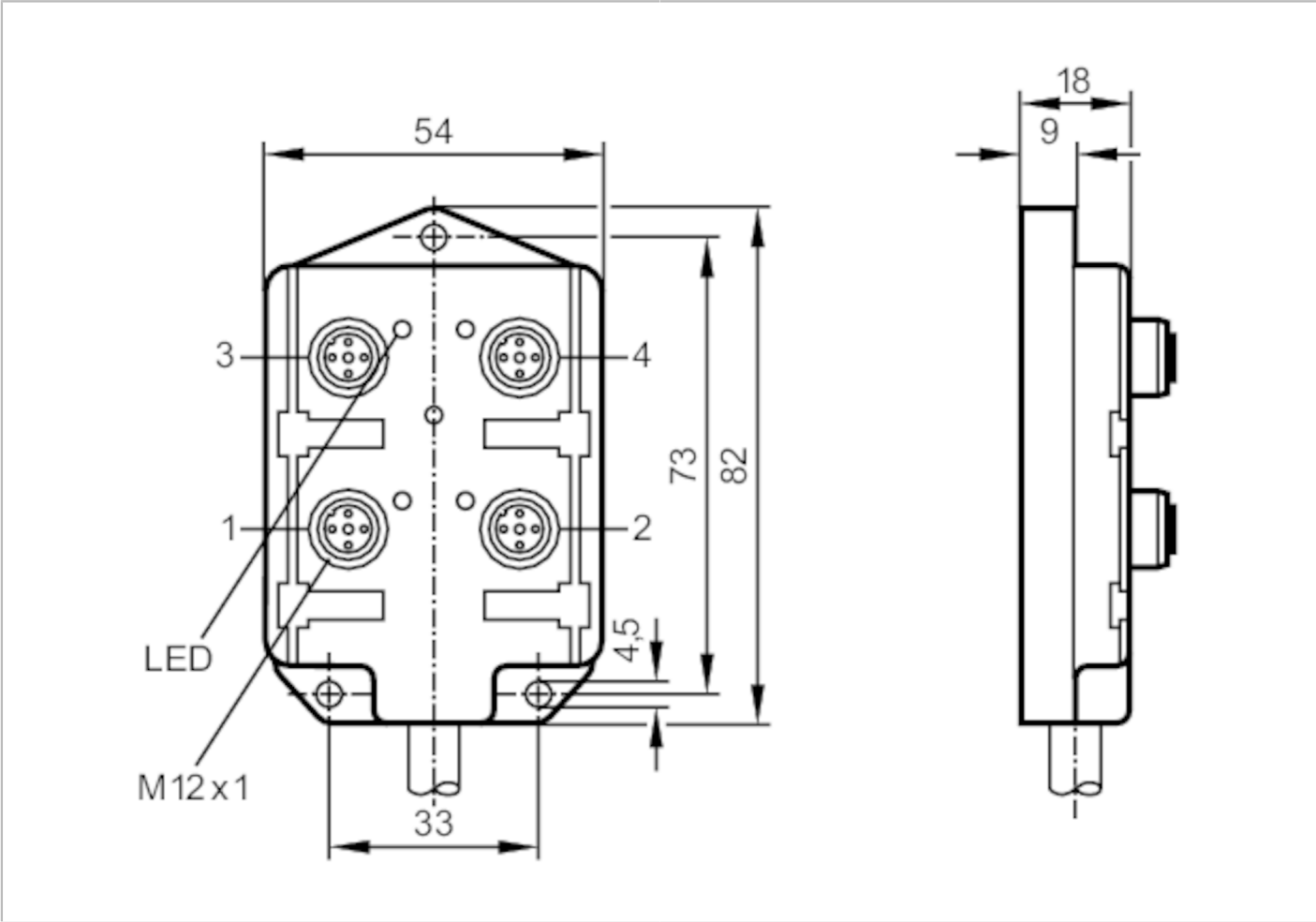

Data kelistrikan

Tegangan pengoperasian	[V]	10...30 DC
Beban arus maks. per modul/slot	[A]	4
Total beban arus maks.	[A]	12

Kondisi pengoperasian

Suhu sekitar	[°C]	-15...90
Perlindungan		IP 67

Data teknis

Dimensi	[mm]	18 x 54 x 82
Jumlah port kotak splitter		4

Elemen display/pengoperasian

Display	status peralihan	4 x LED, kuning
	operasi	1 x LED, hijau

Keterangan

Jumlah paket	1 buah
--------------	--------

E10290



Kotak splitter


ZDO4H045MSS0,03A07

Koneksi listrik

Kabel: 0.35 m, PUR / PVC; 4 x 0.34 mm² + 3 x 0.75 mm²

Koneksi listrik - slot

Konektor: 4 x M12; pengkodean: A; Torsi pengencangan: 0.5 Nm

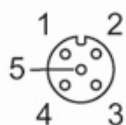

Koneksi

BN	1 (1...4)	C
BU	3 (1...4)	C
GN/YE	5 (1...4)	C
WH	4 (1)	C
GN	4 (2)	C
YE	4 (3)	C
GY	4 (4)	C

	Warna core :
BN =	coklat
BU =	biru
GN =	hijau
GN/YE =	hijau/kuning
GY =	abu-abu
WH =	putih
YE =	kuning