


# E10301



## Kabel koneksi dengan soket

ADOGH040MSS0010A03

Produk tidak tersedia - entri arsip

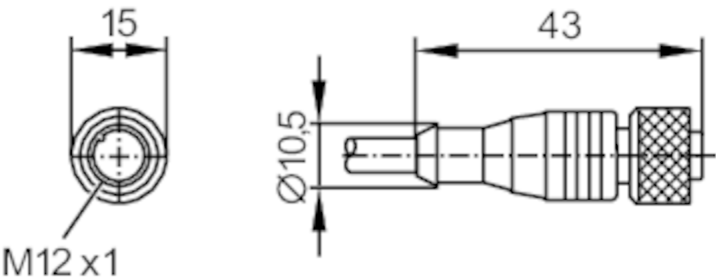

| Data kelistrikan                                     |      |                          |
|------------------------------------------------------|------|--------------------------|
| Tegangan pengoperasian                               | [V]  | < 250 AC / < 300 DC      |
| Kondisi pengoperasian                                |      |                          |
| Suhu sekitar                                         | [°C] | -25...90                 |
| Perlindungan                                         |      | IP 67                    |
| Data teknis                                          |      |                          |
| Dimensi                                              | [mm] | 15 x 15 x 43             |
| Material                                             |      | TPU                      |
| Material bodi detakan                                |      | TPU                      |
| Material mur                                         |      | kuningan, berlapis nikel |
| Keterangan                                           |      |                          |
| Jumlah paket                                         |      | 1 buah                   |
| Koneksi listrik                                      |      |                          |
| Kabel: 10 m, PUR / PVC, oranye, Ø 5 mm; 3 x 0.34 mm² |      |                          |
| Koneksi listrik - soket                              |      |                          |

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel




# E10301



## Kabel koneksi dengan soket

ADOGH040MSS0010A03

### Koneksi

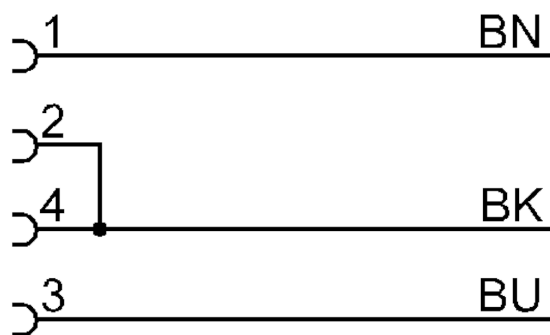

BN =  
BK =  
BU =

Warna core :  
coklat  
hitam  
biru