


E10318



Kabel koneksi dengan soket

ADOAH042VAS0005E03

Produk tidak tersedia - entri arsip

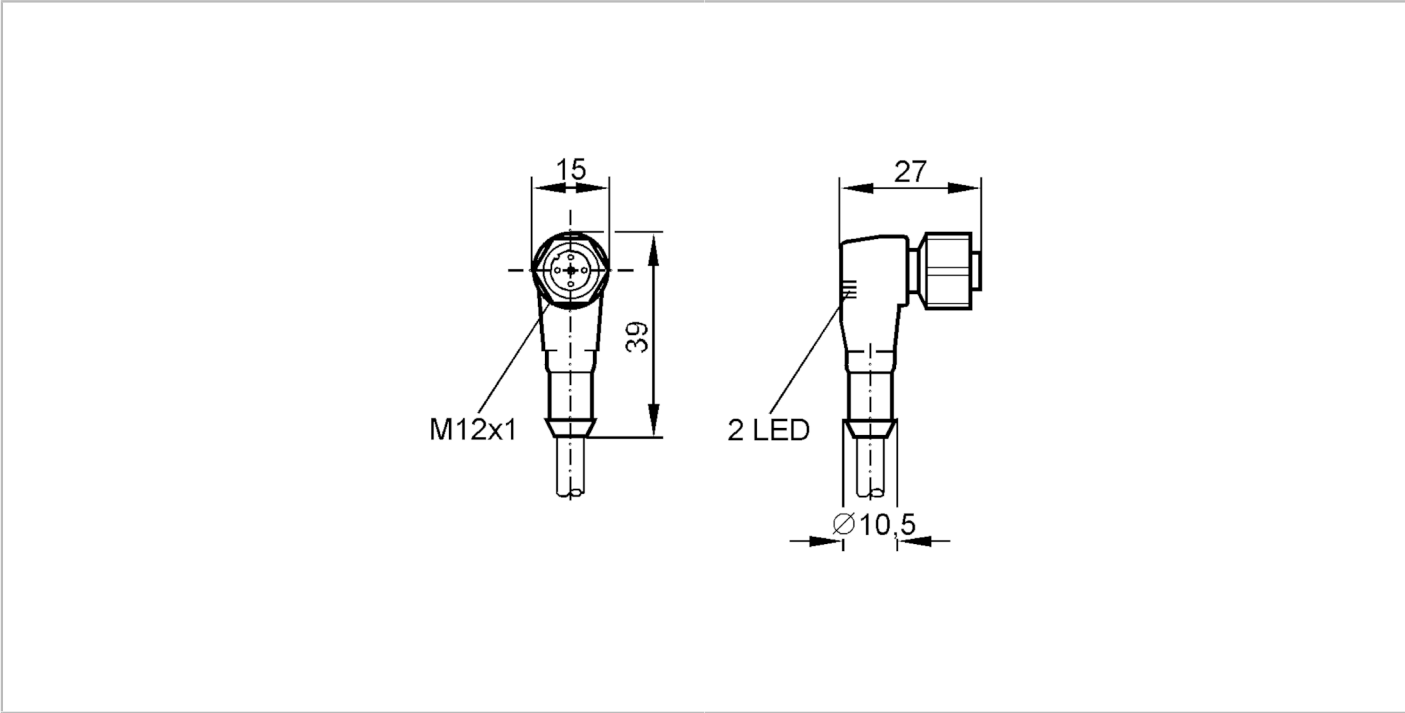

Data kelistrikan	
Tegangan pengoperasian	[V] 10...30 DC
Output	
Desain kelistrikan	PNP
Kondisi pengoperasian	
Suhu sekitar	[°C] -25...90
Perlindungan	IP 67
Data teknis	
Material	TPU transparan
Material bodi detakan	TPU, transparan
Material mur	baja tahan karat (1.4404 / 316L)
Keterangan	
Jumlah paket	1 buah

E10318



Kabel koneksi dengan soket

 
ADOAH042VAS0005E03

Koneksi listrik


Kabel: 5 m, PVC, oranye, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: TPU, transparan; Penguncian: baja tahan karat (1.4404 / 316L); Torsi pengencangan: 0.5 Nm



Koneksi

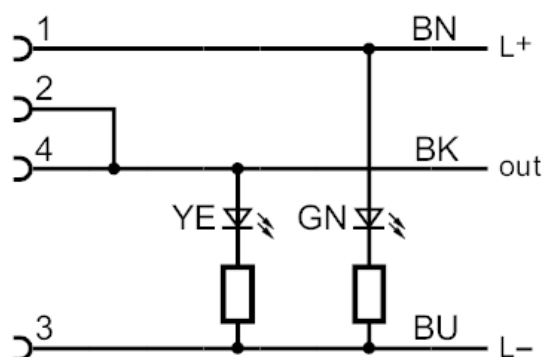

BK =
BN =
BU =

Warna core :
hitam
coklat
biru