


E10334



Kabel koneksi dengan soket

ADOAH040VAS0010E02

Produk tidak tersedia - entri arsip

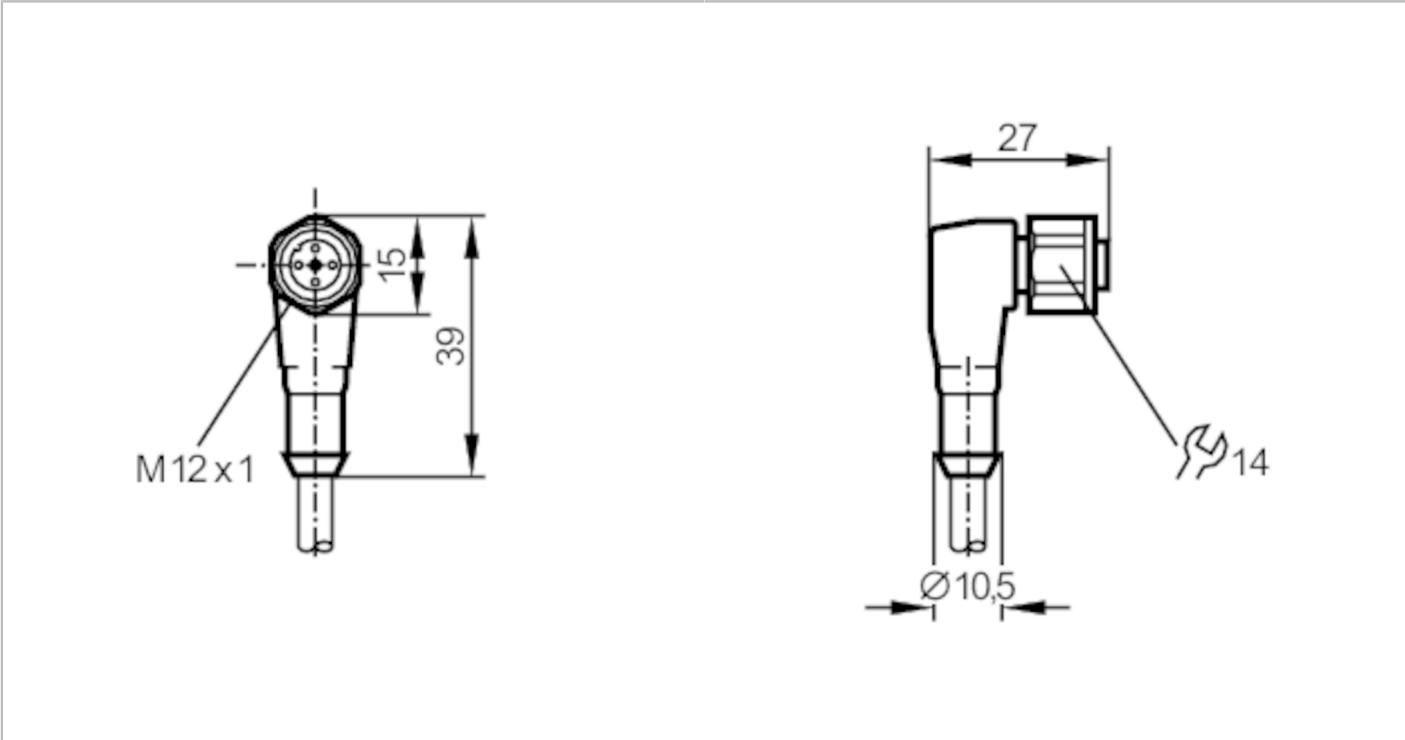

Data kelistrikan		
Tegangan pengoperasian	[M]	< 250 AC / < 300 DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67
Data teknis		
Dimensi	[mm]	27 x 15 x 39
Material		TPU
Material bodi detakan		TPU
Material mur		baja tahan karat (1.4404 / 316L)
Keterangan		
Jumlah paket		1 buah
Koneksi listrik		
Kabel: 10 m, PVC, oranye, Ø 5 mm; 2 x 0.34 mm² (42 x Ø 0.1 mm)		
Koneksi listrik - soket		

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: baja tahan karat (1.4404 / 316L)




E10334



Kabel koneksi dengan soket

ADOAH040VAS0010E02

Koneksi

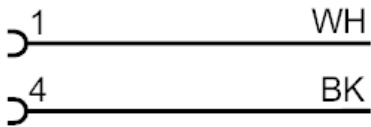

BK =	Warna core :
WH =	hitam
	putih