


E10359



Kabel koneksi dengan soket


AD0GB030PLS0010E03

Produk tidak tersedia - entri arsip

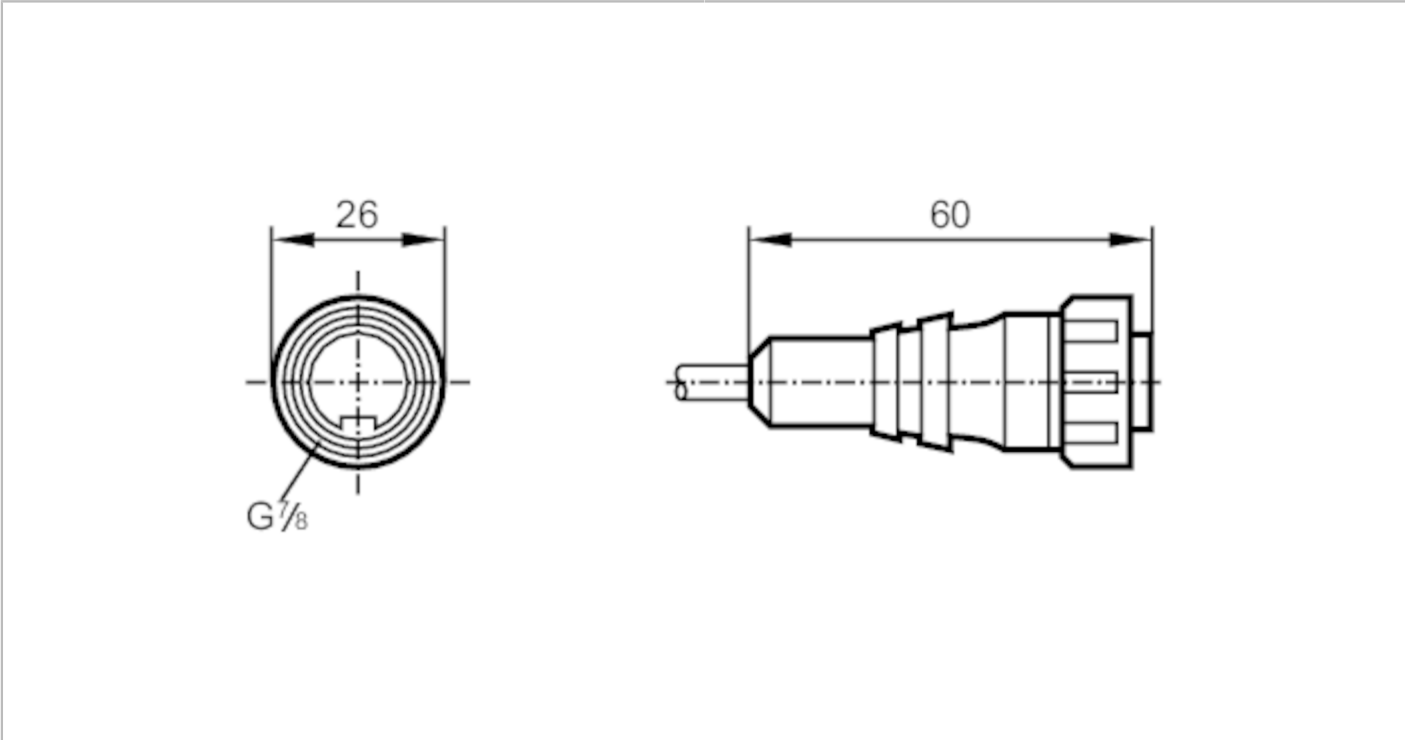

| Data kelistrikan                                                  |      |              |
|-------------------------------------------------------------------|------|--------------|
| Tegangan pengoperasian                                            | [V]  | < 250 AC     |
| Kondisi pengoperasian                                             |      |              |
| Suhu sekitar                                                      | [°C] | -40...90     |
| Perlindungan                                                      |      | IP 68        |
| Data teknis                                                       |      |              |
| Dimensi                                                           | [mm] | 26 x 26 x 60 |
| Material                                                          |      | TPU          |
| Material bodi detakan                                             |      | TPU          |
| Material mur                                                      |      | PA 6 GV      |
| Keterangan                                                        |      |              |
| Jumlah paket                                                      |      | 1 buah       |
| Koneksi listrik                                                   |      |              |
| Kabel: 10 m, PVC, oranye, Ø 7.2 mm; 3 x 0.75 mm² (22 x Ø 0.2 mm ) |      |              |
| Koneksi listrik - soket                                           |      |              |

Konektor: 1 x 7/8", lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: PA 6 GV

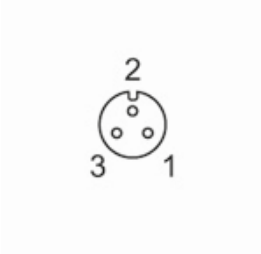


# E10359



## Kabel koneksi dengan soket

ADOGB030PLS0010E03

### Koneksi

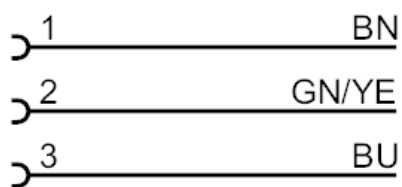

|         |              |              |
|---------|--------------|--------------|
| BN =    | Warna core : | coklat       |
| BU =    |              | biru         |
| GN/YE = |              | hijau/kuning |