

Kabel koneksi dengan soket

ADOGH040MSS0010A02

Produk tidak tersedia - entri arsip



Data kelistrikan

Tegangan pengoperasian	[V]	< 250 AC / < 300 DC
------------------------	-----	---------------------

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67

Data teknis

Dimensi	[mm]	15 x 15 x 43
Material		TPU
Material bodi detakan		TPU
Material mur		kuningan, berlapis nikel

Keterangan


Jumlah paket		1 buah
--------------	--	--------

Koneksi listrik

Kabel: 10 m, PUR / PVC, oranye, Ø 5 mm; 2 x 0.34 mm² (180 x Ø 0.05 mm)

Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel; Torsi pengencangan: 0.5 Nm

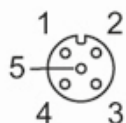


E10394



Kabel koneksi dengan soket

ADOGH040MSS0010A02

Koneksi

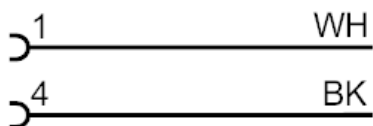

BK =	Warna core :
WH =	hitam
	putih