


Kabel jumper dengan soket katup

VVDAB031MSS0001H03STGH030MSS

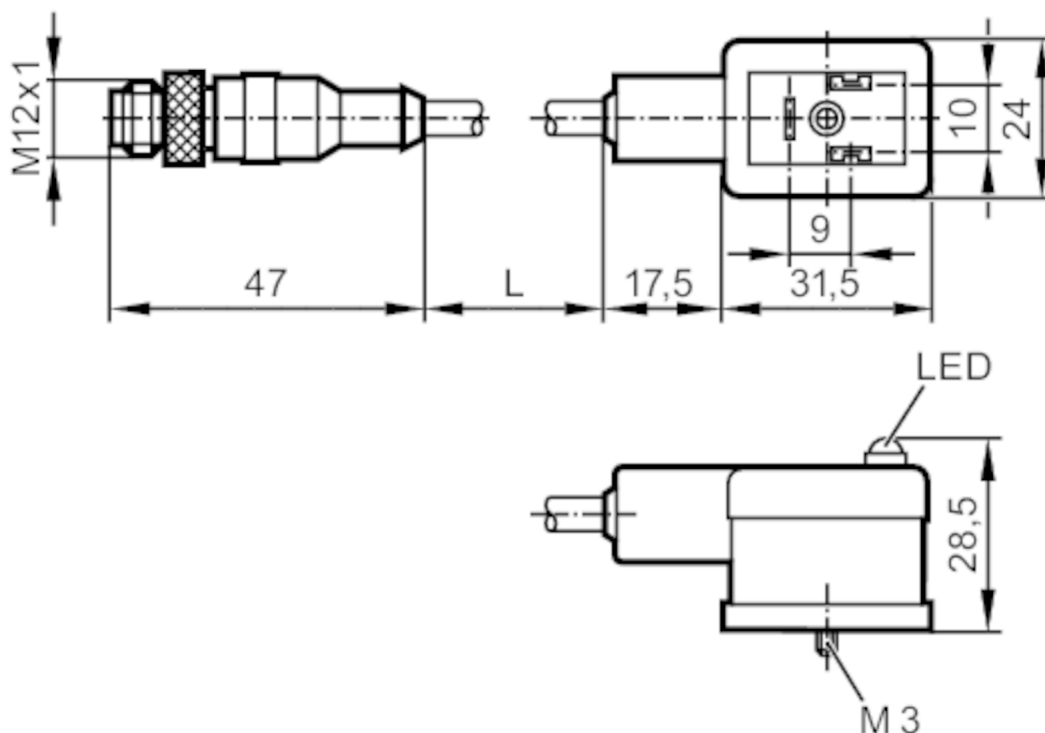

Aplikasi		
Fitur khusus	Bebas dari silikon; Bebas halogen; Kontak berlapis emas	
Bebas dari silikon	ya	
Data kelistrikan		
Tegangan pengoperasian	[V]	< 24 AC/DC
Pelindung tegangan berlebih		ya; (VDR)
Total beban arus maks.	[A]	3
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...80
Perlindungan		IP 67
Data teknis		
Berat	[g]	93
Material		PUR
Material bodi detakan		PUR
Material mur		kuningan, berlapis nikel
Elemen display/pengoperasian		
Display	operasi	1 x LED, kuning
Aksesori		
Item dikirim	sekrup	
	panel untuk pelabelan	

Kabel jumper dengan soket katup

VVDAB031MSS0001H03STGH030MSS

 
Keterangan

Jumlah paket

1 buah

Koneksi listrik - colokan


Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas; Torsi pengencangan: 0.7...0.9 Nm



Koneksi listrik

Kabel: 1 m, PUR, Bebas halogen, hitam, Ø 5 mm; 3 x 0.5 mm² (42 x Ø 0.1 mm)

Koneksi

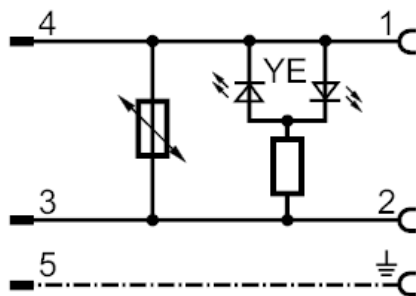

Koneksi listrik - soket

Konektor: 1 x katup tipe B DIN, bersiku; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel; Kontak: kuningan berlapis nikel; Torsi pengencangan: 0.7...0.9 Nm

