


E11510



Soket berkabel

SDOAH042MSSFKPG

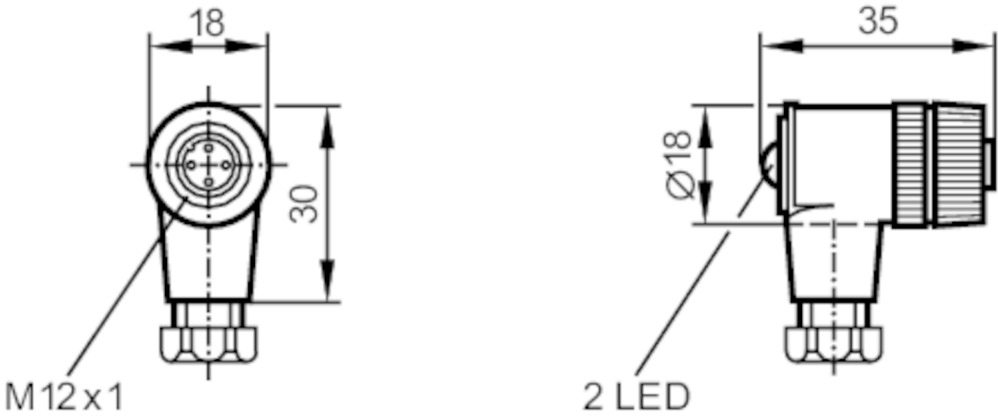

Aplikasi		
Fitur khusus	Bebas dari silikon; Kontak berlapis emas	
Bebas dari silikon	ya	
Data kelistrikan		
Tegangan pengoperasian	[V]	10...30 DC
Total beban arus maks.	[A]	4; (...40 °C)
Output		
Desain kelistrikan	PNP	
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...85
Perlindungan	IP 68	
Data teknis		
Berat	[g]	28.6
Dimensi	[mm]	30 x 18 x 35
Material	PA	
Material bodi detakan	PA	
Material mur	kuningan, berlapis nikel	
Elemen display/pengoperasian		
Display	status peralihan	1 x LED, kuning
	operasi	1 x LED, hijau
Keterangan		
Jumlah paket	1 buah	

E11510



Soket berkabel

SDOAH042MSSFKPG

Koneksi listrik

terminal sekrup: ...0.75 mm²; Selubung kabel: Ø 4...6 mm

Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: PA; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas



Koneksi

