




Colokan adaptor

ESTGH040MSS0,08E04 (M16)

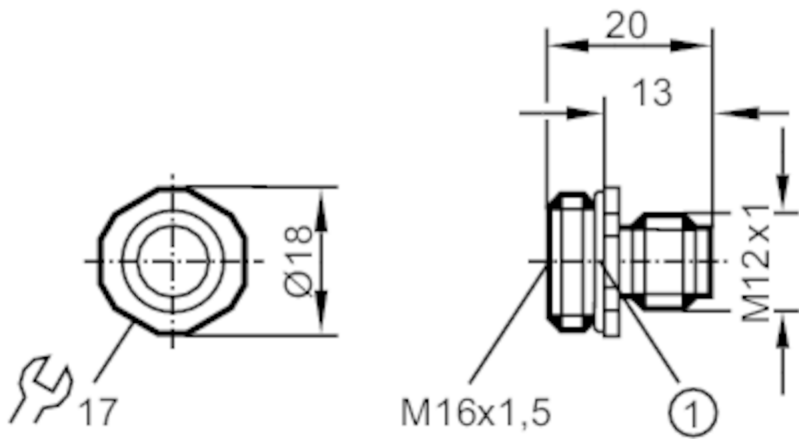

1 O-ring



Data kelistrikan		
Tegangan pengoperasian	[V]	< 250 AC/DC
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...85
Perlindungan		IP 68
Data teknis		
Berat	[g]	30.743
Ulir pemasangan		M16 x 1,5
Material		seng tuang berlapis nikel
Material bodi detakan		seng tuang, berlapis nikel
Keterangan		
Jumlah paket		1 buah

**Colokan adaptor**

ESTGH040MSS0,08E04 (M16)

Koneksi listrikKabel: 0.08 m, PVC; 4 x 0.34 mm²**Koneksi listrik - colokan**

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: seng tuang, berlapis nikel

**Koneksi**

1	BN
2	WH
3	BU
4	BK

BK =
BN =
BU =
WH =

Warna core :
hitam
coklat
biru
putih