


E11535



Soket berkabel

SDOAH030MSSFKPG

Produk tidak tersedia - entri arsip

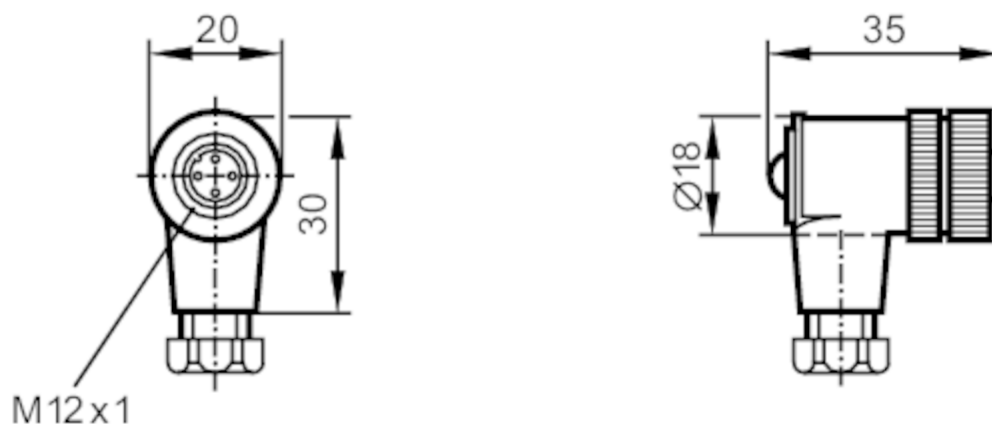

Data kelistrikan

Tegangan pengoperasian [V] < 250 AC

Kondisi pengoperasian

Suhu sekitar [°C] -40...85

Perlindungan IP 67

Data teknis

Berat [g] 25

Dimensi [mm] 35 x 20 x 30

Material PBT

Material bodi detakan PBT

Material mur PA

Keterangan

Jumlah paket 1 buah

E11535



Soket berkabel

SDOAH030MSSFKPG

Koneksi listrik

terminal sekrup: ...0.75 mm²; Selubung kabel: Ø 6...8 mm

Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: C; Bodi cetakan: PBT; Penguncian: PA



Koneksi

