


Colokan berkabel

SSTGF030MSSFPKG

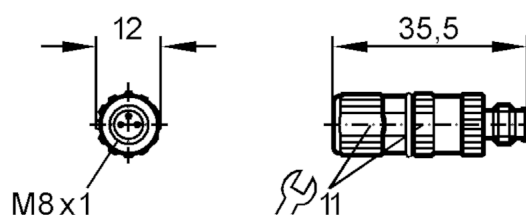

Aplikasi

Fitur khusus

Kontak berlapis emas

Data kelistrikan

Tegangan pengoperasian

[V]

< 50 AC / < 75 DC

Kelas perlindungan

III

Total beban arus maks.

[A]

4

Kondisi pengoperasian

Suhu sekitar

[°C]

-25...90

Perlindungan

IP 68

Data teknis

Berat

[g]

14.8

Material

PA

Material bodi detakan

PA

Material mur

kuningan, berlapis nikel

Keterangan

Jumlah paket

1 buah

E11550



Colokan berkabel

SSTGF030MSSFPKG

Koneksi listrik

teknologi perpindahan isolasi: 0.14...0.38 mm²; Isolasi core: PVC / TPE; (Ø 1.0...1.6 mm); Selubung kabel: Ø 3...5 mm

Koneksi listrik - colokan

Konektor: 1 x M8, lurus; pengkodean: A; Bodi cetakan: PA; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas



Koneksi

