


Soket berkabel

SDOGF040MSSFPKG

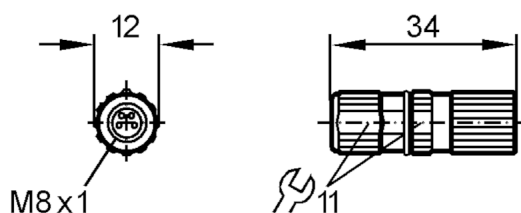

Aplikasi

Fitur khusus

Kontak berlapis emas

Data kelistrikan

Tegangan pengoperasian [V]

< 45 AC / < 70 DC

Kelas perlindungan

III

Total beban arus maks. [A]

4

Kondisi pengoperasian

Suhu sekitar [°C]

-25...90

Perlindungan

IP 68

Data teknis

Berat [g]

17.1

Material

PA

Material bodi detakan

PA

Material mur

kuningan, berlapis nikel

Keterangan

Jumlah paket

1 buah

E11553



Soket berkabel

SDOGF040MSSFPKG

Koneksi listrik

teknologi perpindahan isolasi: 0.14...0.38 mm²; Isolasi core: PVC / TPE; (Ø 1.0...1.6 mm); Selubung kabel: Ø 3...5 mm

Koneksi listrik - soket

Konektor: 1 x M8, lurus; pengkodean: A; Bodi cetakan: PA; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas



Koneksi

