


E11564



Kabel koneksi

VDOAF032MSS01,5H03STGH030MSS

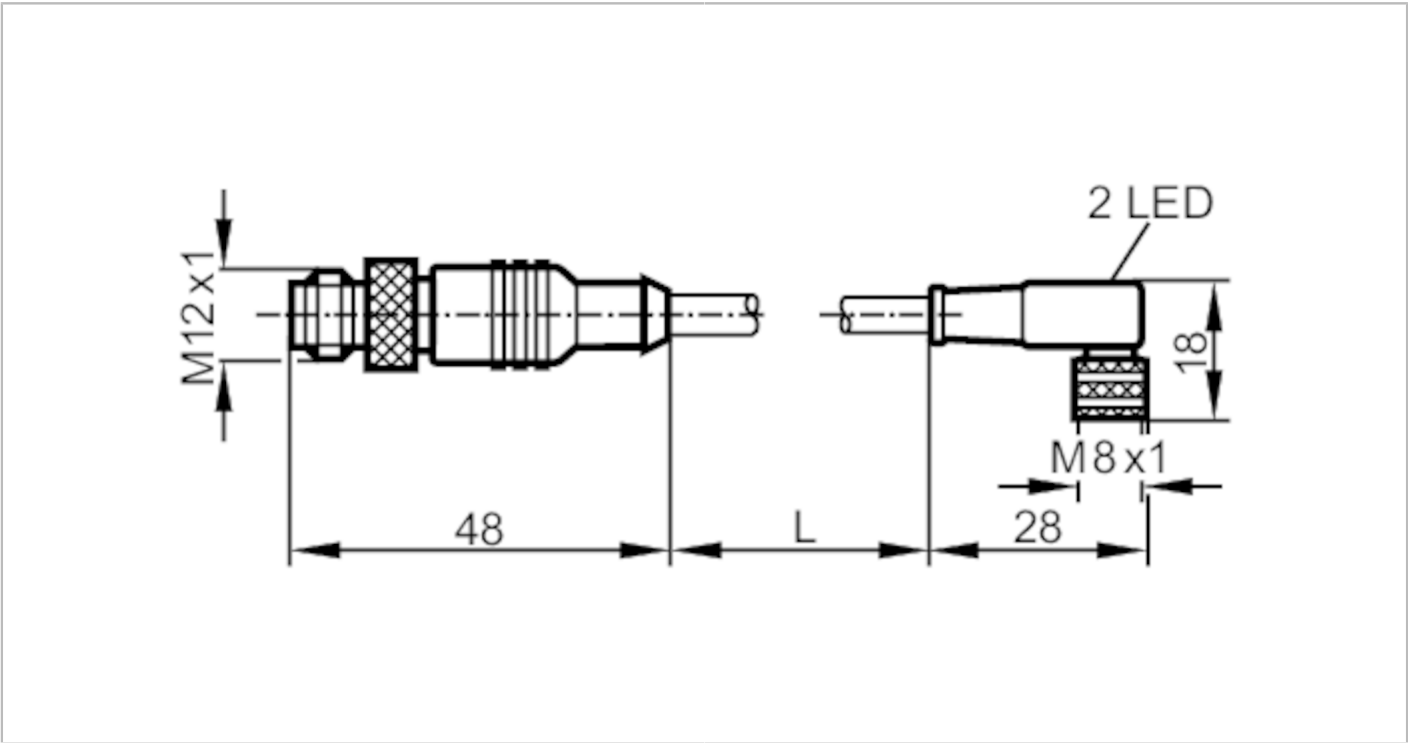

Aplikasi		
Fitur khusus	Bebas dari silikon; Bebas halogen; Kontak berlapis emas	
Bebas dari silikon	ya	
Data kelistrikan		
Tegangan pengoperasian	[V]	10...30 DC
Kelas perlindungan		III
Total beban arus maks.	[A]	3
Output		
Desain kelistrikan	PNP	
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...85
Perlindungan		IP 68
Data teknis		
Berat	[g]	56.2
Material		PUR
Material bodi detakan		PUR
Material mur		kuningan, berlapis nikel
Elemen display/pengoperasian		
Display	status peralihan	1 x LED, kuning
	operasi	1 x LED, hijau
Keterangan		
Jumlah paket	1 buah	

Kabel koneksi

VDOAF032MSS01,5H03STGH030MSS

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas; Torsi pengencangan: 0.7...0.9 Nm



Koneksi listrik

Kabel: 1.5 m, PUR, Bebas halogen, hitam, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Koneksi



Koneksi listrik - Buchse





Kabel koneksi

VDOAF032MSS01,5H03STGH030MSS

Koneksi



Koneksi listrik - soket

Konektor: 1 x M8, bersiku; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas; Torsi pengencangan: 0.6...0.7 Nm