


E11566



Splitter T

T SPLITTER M12/2XUS

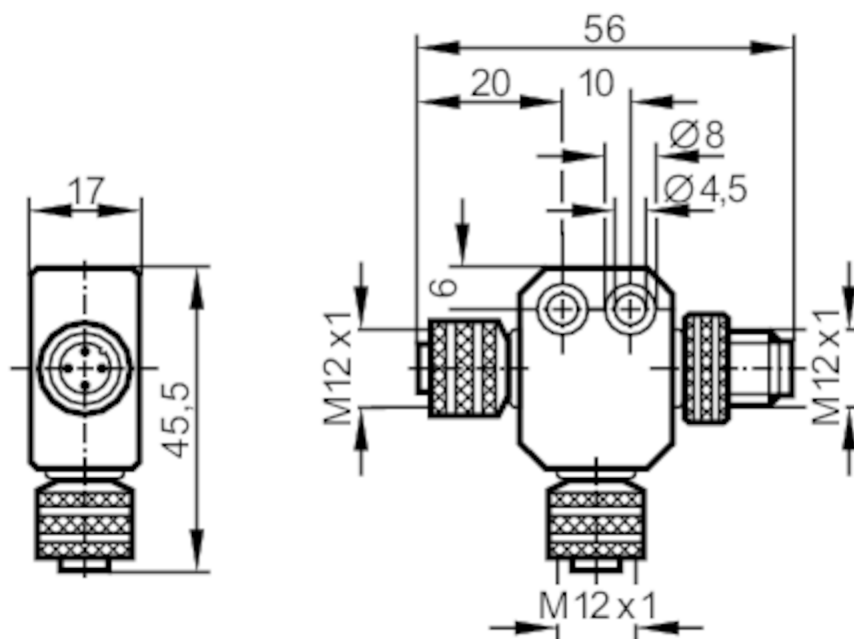

Aplikasi	
Desain	untuk sensor tekanan PNI
Data kelistrikan	
Tegangan pengoperasian [V]	< 30 AC / < 36 DC
Beban arus maks. per modul/ slot [A]	3
Total beban arus maks. [A]	3
Kondisi pengoperasian	
Suhu sekitar [°C]	-25...90
Perlindungan	IP 68
Data teknis	
Berat [g]	38.2
Material	PUR
Keterangan	
Keterangan	orientasi konektor A/B horizontal (untuk sensor vertikal)
Jumlah paket	1 buah

Splitter T

T SPLITTER M12/2XUS

Koneksi listrik

Koneksi

