


Splitter Y

Safety splitter box

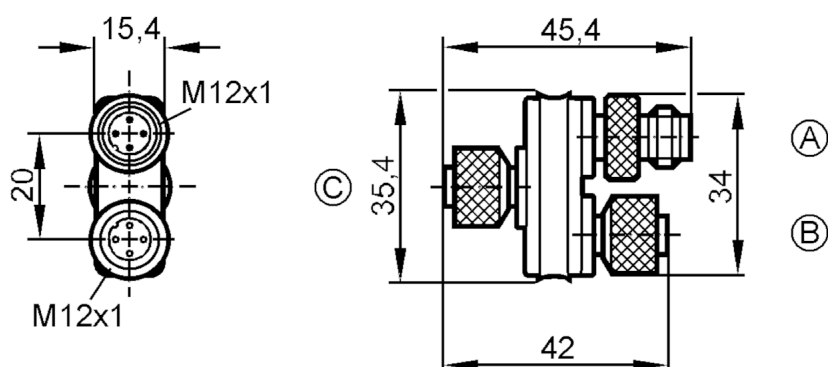

Aplikasi

Desain	T-piece untuk koneksi pseudo-serial sensor fail-safe
--------	--

Data kelistrikan

Tegangan pengoperasian	[V]	< 30 AC / < 36 DC
Beban arus maks. per modul/slot	[A]	4
Total beban arus maks.	[A]	4

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...90
Perlindungan		IP 68

Data teknis

Berat	[g]	31.4
Material		PUR
Material bodi detakan		PUR
Material mur		kuningan, berlapis nikel

Keterangan


Jumlah paket	1 buah
--------------	--------

Splitter Y

Safety splitter box

Koneksi listrik

Koneksi

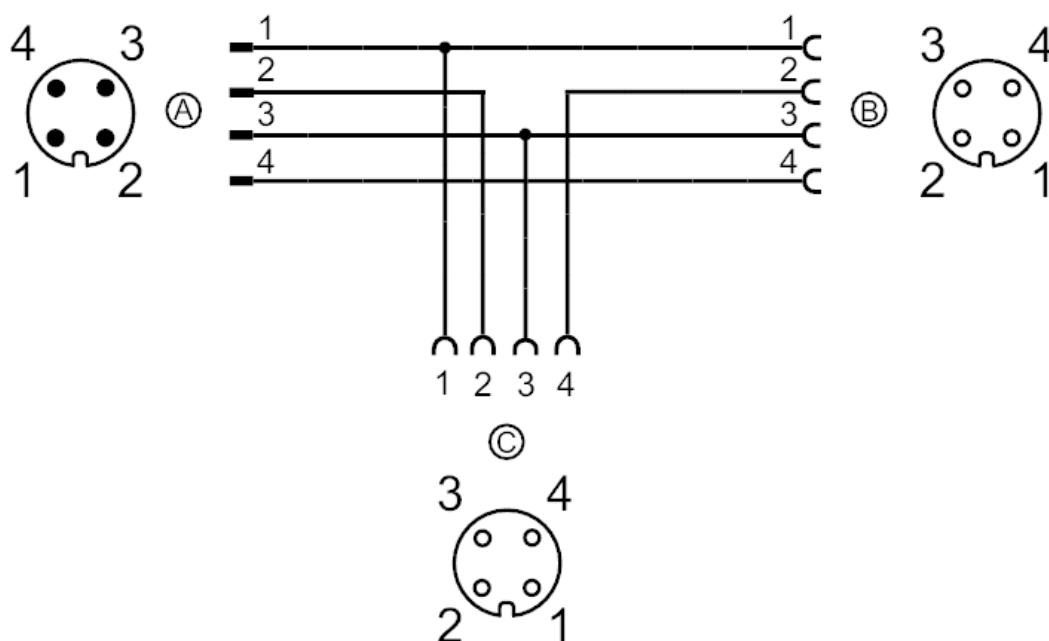

Koneksi listrik - colokan

Konektor: 1 x M12; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel

Koneksi listrik - soket

Konektor: 1 x M12; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel

Konektor: 1 x M12; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel