




Kabel koneksi

VDOGQ090PLS0003E03STGF040MSS

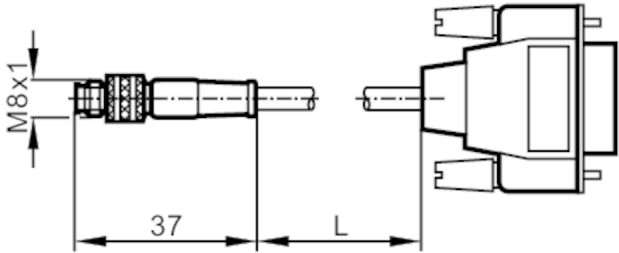


Data kelistrikan		
Tegangan pengoperasian	[V]	< 60 AC / < 75 DC
Kelas perlindungan		III
Kondisi pengoperasian		
Suhu sekitar	[°C]	-25...85
Perlindungan		IP 50
Data teknis		
Berat	[g]	113.9
Material		PUR
Material bodi detakan		PUR
Material mur		kuningan, berlapis nikel
Keterangan		
Jumlah paket		1 buah
Koneksi listrik		
Kabel: 3 m, PVC, hitam, Ø 5 mm; 3 x 0.25 mm² (32 x Ø 0.1 mm)		
Koneksi listrik - colokan		
Konektor: 1 x M8, lurus; pengkodean: A; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel		



**Kabel koneksi**

VDOGQ090PLS0003E03STGF040MSS

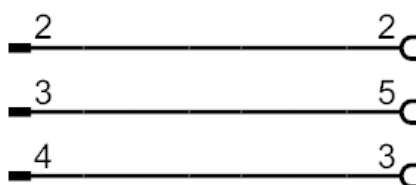Koneksi**Koneksi listrik - soket**

Konektor: 1 x Sub D, lurus; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel

