


Kabel koneksi

VDOAH043MSS0003H04STGH040MSS

Produk tidak tersedia - entri arsip

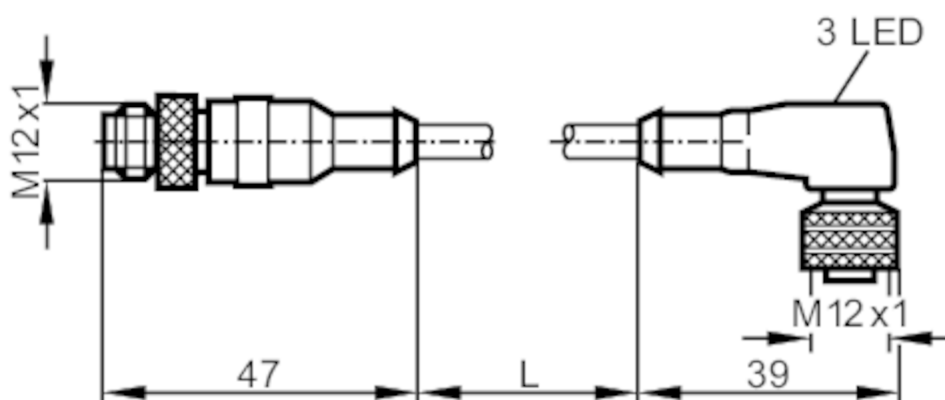

Aplikasi

Fitur khusus	Bebas dari silikon; Bebas halogen; Kontak berlapis emas
Bebas dari silikon	ya

Data kelistrikan

Tegangan pengoperasian	[V]	10...30 DC
Total beban arus maks.	[A]	3

Output

Desain kelistrikan	PNP
--------------------	-----

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...85
Perlindungan		IP 68

Data teknis

Material	PUR
Material bodi detakan	PUR
Material mur	kuningan, berlapis nikel

Elemen display/pengoperasian

Display	status peralihan	2 x LED, kuning
	operasi	1 x LED, hijau

Keterangan

Jumlah paket	1 buah
--------------	--------

Kabel koneksi

VDOAH043MSS0003H04STGH040MSS

Koneksi listrik - colokan

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas; Torsi pengencangan: 0.7...0.9 Nm



Koneksi listrik

Kabel: 3 m, PUR, Bebas halogen, hitam, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Koneksi



Koneksi listrik - soket

Konektor: 1 x M12, bersiku; pengkodean: A; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel; Kontak: dilapisi emas; Torsi pengencangan: 0.7...0.9 Nm

