


E11601



Soket adaptor

EDOGH080MSS00,5E08 (PG9)

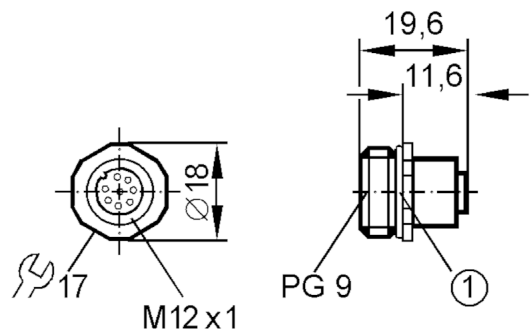

1 O-ring



Data kelistrikan

Tegangan pengoperasian	[V]	< 30 AC / < 36 DC
------------------------	-----	-------------------

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...90
--------------	------	----------

Perlindungan		IP 67
--------------	--	-------

Data teknis

Berat	[g]	33
-------	-----	----

Ulir pemasangan		PG 9
-----------------	--	------

Material		kuningan berlapis nikel
----------	--	-------------------------

Material bodi detakan		kuningan, berlapis nikel
-----------------------	--	--------------------------

Keterangan

Jumlah paket		1 buah
--------------	--	--------

E11601



Soket adaptor


EDOGH080MSS00,5E08 (PG9)

Koneksi listrik

Kabel: 0.5 m, PVC; 8 x 0.25 mm² (14 x Ø 0.15 mm)

Koneksi listrik - soket

Konektor: 1 x M12, lurus; pengkodean: A; Bodi cetakan: kuningan, berlapis nikel

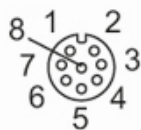

Koneksi

1	WH
2	BN
3	GN
4	YE
5	GY
6	PK
7	BU
8	RD

warna sesuai DIN
47100

Warna core :

BN =	coklat
BU =	biru
GN =	hijau
GY =	abu-abu
PK =	merah muda
RD =	merah
WH =	putih
YE =	kuning