


E11627



Splitter T

T SPLITTER M12/2XUS

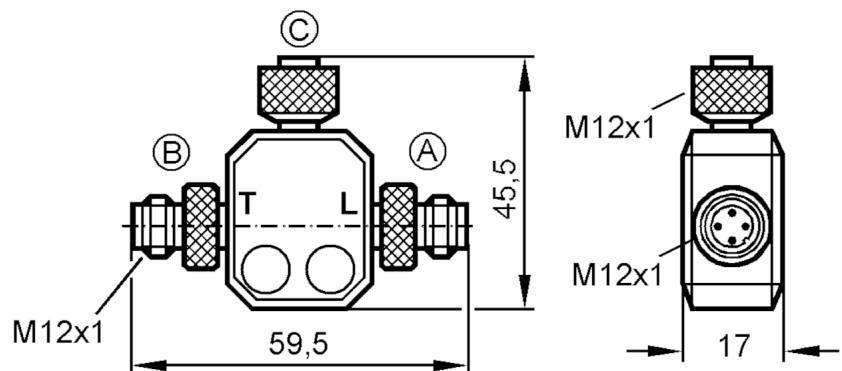

Data kelistrikan

Tegangan pengoperasian	[V]	< 30 AC / < 36 DC
Beban arus maks. per modul/ slot	[A]	3
Total beban arus maks.	[A]	3

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...90
Perlindungan		IP 68

Data teknis

Berat	[g]	39.7
Material		PUR
Material bodi detakan		PUR
Material mur		kuningan, berlapis nikel

Aksesori

Item dikirim		Tutup pelindung: 1
--------------	--	--------------------

Keterangan


Jumlah paket		1 buah
--------------	--	--------

Splitter T

T SPLITTER M12/2XUS

Koneksi listrik

Koneksi

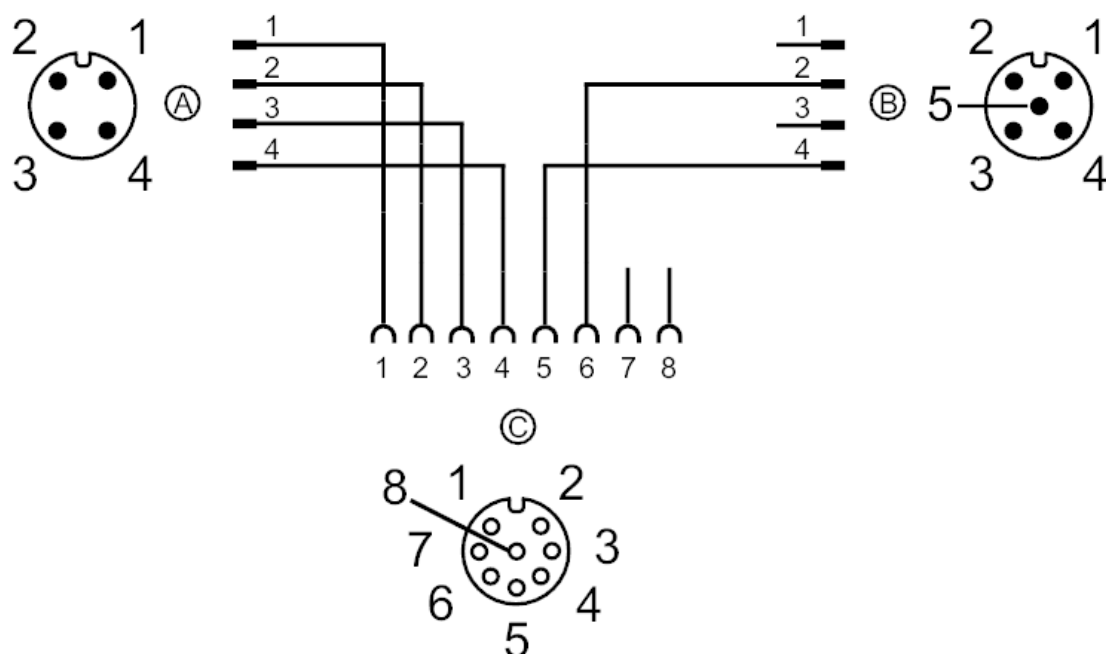

Konektor: 1 x M12; Bodi cetakan: PUR; Penguncian: kuningan, berlapis nikel