


E11661



Kabel koneksi dengan soket

ADOGA030MSS0010E03

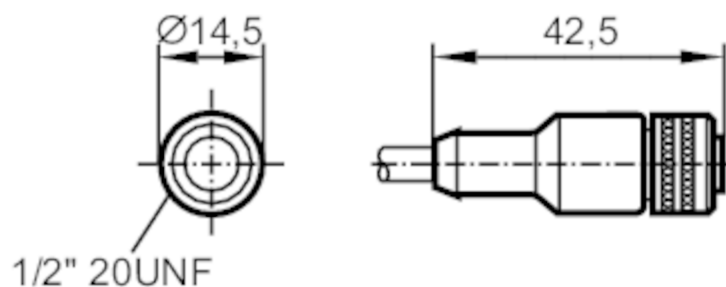

Aplikasi

Fitur khusus	Kesesuaian rantai tarik
--------------	-------------------------

Data kelistrikan

Tegangan pengoperasian	[V]	< 250 AC/DC
Total beban arus maks.	[A]	4; (40° C)

Kondisi pengoperasian

Suhu sekitar	[°C]	-25...90
Perlindungan		IP 67

Data teknis

Berat	[g]	404.431
Dimensi	[mm]	14.5 x 14.5 x 42.5
Material		TPU
Material bodi detakan		TPU
Material mur		kuningan, berlapis nikel
Kesesuaian rantai tarik		ya
Kesesuaian rantai tarik	radius pembengkokan untuk penggunaan yang fleksibel	min. 10 x diameter kabel
	kecepatan pergerakan	maks. 3,3 m/dtk untuk panjang pergerakan horizontal 5 m dan akselerasi maks. 5 m/dtk ²
	siklus pembengkokan	> 2 Mio.
	ketegangan torsional	± 180 °/m

Keterangan

Jumlah paket	1 buah
--------------	--------

E11661



Kabel koneksi dengan soket

ADOGA030MSS0010E03

Koneksi listrik


Kabel: 10 m, PVC, kuning, Ø 5.2 mm; 3 x (42 x Ø 0.1 mm) / AWG 22

Koneksi listrik - soket

Konektor: 1 x 1/2", lurus; pengkodean: C; Bodi cetakan: TPU; Penguncian: kuningan, berlapis nikel



Koneksi

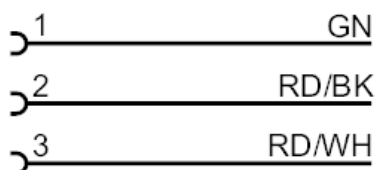

GN =	Warna core :
RD/BK =	hijau
RD/WH =	merah/hitam
	merah/putih